

DC Connector, Plug, 5.5x2.1 mm, 2-pole, solder terminal

**Description**

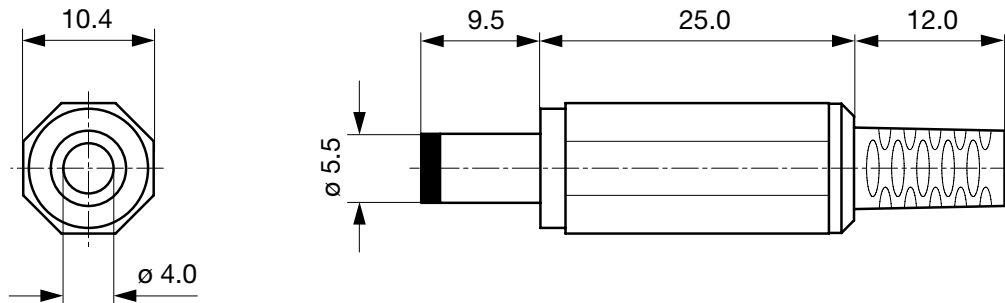
- Solder terminal:
for cable mounting
- Low Voltage DC Plug and Socket
- DC Plug: 2-pole, straight

Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [RoHS](#), [CHINA-RoHS](#), [Mating Connectors](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#)

Technical Data

| | | | |
|-----------------------|--------------------|---------------------------|-------------------------------|
| Diameter | 5.5 mm / 2.1 mm | Allowable Operation Temp. | -20 °C to 70 °C |
| Number of Poles | 2-pole | Terminal | solder terminal nickel-plated |
| Ratings DC | 0.5 A / 12 VDC | Style | straight |
| Dielectric Strength | 500 VDC | Lifetime | 5000 Insertions |
| Insulation Resistance | > 100 MΩ @ 500 VDC | | |

Dimensions

Cable diameter max. 4.0 mm

Variants

| Product group | Diameter [mm] | Number of Poles | Terminal | Order Number |
|----------------|---------------|-----------------|-----------------|--------------|
| DC Plug/Socket | 5.5 | 2-pole | solder terminal | 4840.1200 |

Packaging unit 100 Pcs**Mating Outlets/Connectors****Category / Description**[DC Plug/Socket Overview complete](#)DC Connector, Plug, 6.3 mm, 2.00 mm, 2-pole, solder terminal [4840.2200](#)DC Connector, Socket, 6.0 mm, 2.00 mm, 2-pole, solder terminals for PCB [4840.2201](#)DC Connector, Plug, 5.5x2.1 mm, 2-pole, straight, with cable [4840.5202](#)[DC Plug/Socket further types to 4840 DC-Stecker, verschiedene](#)