



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

| | |
|---|---|
| EU RoHS Directive 2011/65/EU | Compliant |
| EU ELV Directive 2000/53/EC | Compliant |
| China RoHS 2 Directive MIIT Order No 32, 2016 | 有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC |
| Halogen Content | Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free |
| Solder Process Capability | Not reviewed for solder process capability |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

TE Part # 1SNA166763R0200
[PC-E-VA](#)

 
TE Part # 1SNA166628R0300
[TC-E-C5A-2.2](#)

TE Part # 1SNA166972R0000
[TT4-S-VL-INF](#)

TE Part # 1SNA166759R1600
[PO-E-VA](#)




TE Part # 1SNA166977R0000
TC-E-VA-R2-2.2




TE Part # 1SNA166742R0500
TC-DS-VL



 
TE Part # 1SNA166503R2700
TF-DS-VL



 
TE Part # 1SNA166976R0000
CC-E-VA-R2-6.6



TE Part # 1SNA166744R0700
TO-D-VA

 

TE Part # 1SNA166758R1500
PC-DS-VL

 


TE Part # 1SNA166761R0000
PF-E-VA




TE Part # 1SNA166760R1300
PO-D-VA



 
TE Part # 1SNA166627R2200
TC-E-VA-2.2




TE Part # 1SNA166746R0100
TF-D-VA

 


TE Part # 1SNA166523R1200
CC-R-VA

 


TE Part # 1SNA166737R2000
CC-E-VA

 

 
TE Part # 1SNA166722R2100
CC-S-INF-VL-6.6



TE Part # 1SNA166747R0200
TC-E-VA



TE Part # 1SNA166964R0000
TC-TH35-VL

 


TE Part # 1SNA166757R0400
PO-DS-VL

Customers Also Bought



TE Part # 1SNA166578R0100
CPC-1



TE Part # 1SNA166742R0500
TC-DS-VL




TE Part # EL8094-000
D-CT-50M-6.4-OUT-4



TE Part # 1245276-2
HG-Q-Buegel-100



TE Part #9-1393225-6
RY900150 (RY611012)

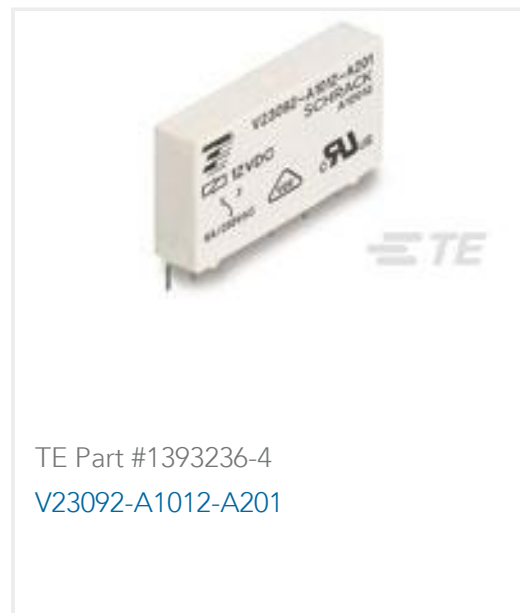

TE Part #1393236-4
V23092-A1012-A201




TE Part #2227303-2
CAGE ASSEMBLY, SFP, .071 TAIL



TE Part #1-2301994-2
RJ45 JACK INT.MAG. 1GB LED 1X1



TE Part #2301996-7
RJ45 JACK INT.MAG. 1GB LED 1X2
INV.

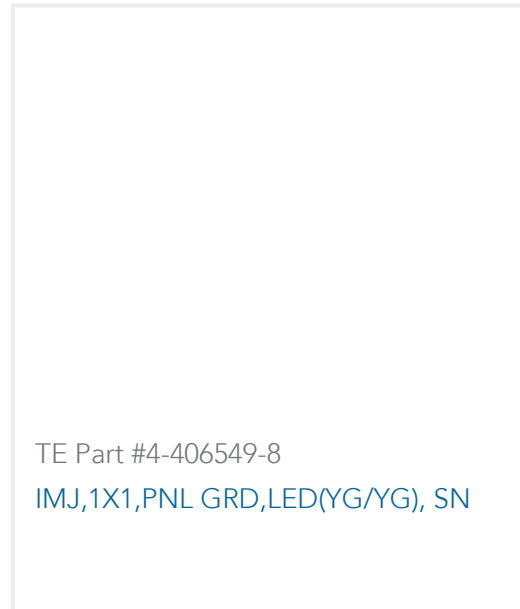

TE Part #4-406549-8
IMJ,1X1,PNL GRD,LED(YG/YG), SN
INV.

Documents

Datasheets & Catalog Pages

ESSAILEC Test Blocks

French

ESSAILEC Test Blocks Catalogue

English

ESSAILEC Test Blocks Catalogue

German

PCVL

English

ENTRELEC Terminal Block - Master Catalog

ENTRELEC Terminal Block - Master Catalog

English

ENTRELEC Terminal Blocks Catalogue (RUS)