



**Ring Terminal**  
**T&B Catalog Number:**

H971  
 78621081518  
 Active

**UPC Number:**  
**Status:**  
**Description:**


Non-Insulated Tubular Ring Terminal, Length 1.65 Inches, Width .77 Inches, Bolt Hole 1/4 Inch, Wire Range 1AN-1/0, Copper, Tin Plated, 100 Pack

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

These non-insulated ring terminals are made of electrolytic copper for high conductivity. They can be installed with crimping tools having a single indenter or double indenter (recommended for solid wire).

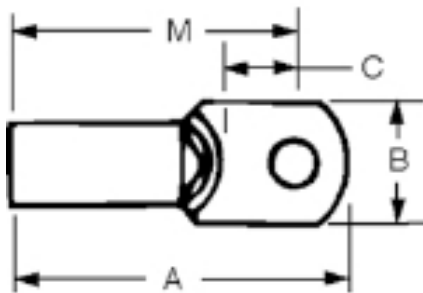

**General**

Insulation Type	Non-Insulated - Tubular
Terminal Series	H
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	1AN-1/0
Stud Size	1/4

**Dimension Information**

Stock Thickness	.05
A (inches)	1.65
B (inches)	.77
C (inches)	.43
M (inches)	1.32

**Specifications**

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0
MIL Specification	MS-20659-115

**Tooling**

Tool Charts	Available on Website
Application Tools	TBM6, TBM6S, WT3185
Recommended Tool	ERG4008, TBM6S

**Packaging**

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	5 lbs. per 100

**Application Support**

T&B Sales Drawings	wsd-000219
--------------------	------------

Overview	Available on Website
Wire Guide Tables	Available on Website

## Notes

Not available on Mylar Tape.

## Certifications

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com