




Actual

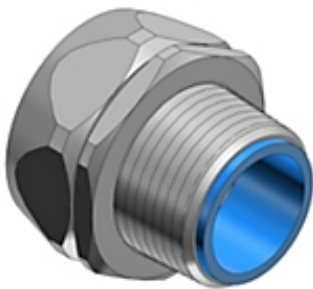

Representative

**Catalog Number:** 5335SST  
**Product ID:** 7TAD012420R0055  
**UPC Number:** 78621097765  
**EAN Number:** 00786210977652  
**Status:** Obsolete  
**Replacement Catalog:** 5335SST6

1-1/4 Inch Straight Stainless Steel Liquidtight Connector

- Available in straight, 45 degree and 90 degree angled configurations to fit conduit from 3/8 inch to 2 inch
- Stronger and more UV-resistant than non-metallic fittings.
- Rated for temperatures up to 105 degrees C (221 degree F)
- Connects metallic-cored liquidtight conduit to a box or enclosure

### Header

3D Model Available on Website

### North American Specifications (UNSPSC)

UNSPSC	39121420 Liquid tight connectors
IGCC	4585 Liquid tight connectors
Brand Name	T&B
Type	Connectors-Straight
Application	Ideal for industrial MRO and OEM applications in food and beverage, pharmaceutical, petrochemical, wastewater, salt water and other corrosive environments.
Standard	UL E23018, CSA
Size	1-1/4 Inch
Material	Stainless Steel

### Packaging

Inner Quantity	5
Inner Dimensions (inches)	7.87x4.92x3.94
Outer Quantity	20
Outer Dimensions (inches)	10.63x8.86x8.86
Weight Uom	61 lbs. per 100

### Documents / Support Tools

Technical Data Sheet CA	Available on Website
Technical Data Sheet Global	wsd-000171

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)