



Blackburn®

Copper Connectors
T&B Catalog Number:

BTC0614
 78378661131
 Active

UPC Number:
Status:
Description:

Type BTC - Copper Single-Conductor, One-Hole Mount (Offset-Tang), Conductor Range 6 Str-14 AWG, Length 1-9/64, Width 3/8 Inch, Height 11/16 Inch, 13/64 Bolt Inch Hole

Features

Uniquely designed pressure bar and notched v-bottom collar provide vise-like grip between conductor and terminal.

Made of electrolytic seamless copper. Screws are zinc-plated steel.

General

Style	Type BTC - Copper Single-Conductor, One Hole Mount (Offset-Tang)
Material	Copper
Wire Range	14 AWG-6 Str.

Dimension Information

Length (inches)	1 3/32
Width (inches)	3/8
Height (inches)	25/32
D (inches)	7/32
E (inches)	13/64
F (inches)	5/64

Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 100

Notes

UL 486A tested.

Certifications

RoHS Compliance	No
-----------------	----

Certifications



File Nbr:
 E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321

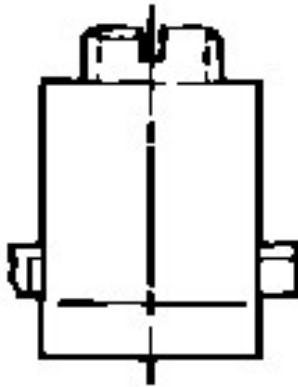
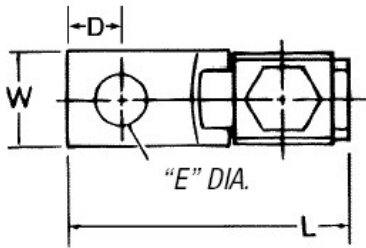


Fig. 2

Email:techsupport@tnb.com