




PRINT

**Grommeting**

**T&B Catalog Number:** GRNY-052-0-C  
**UPC Number:** 72849410129  
**Status:** Active

**Description:**

Extruded Grommeting Black Nylon 6/6 For Max. Panel Thickness .052, 100 Feet Per Roll

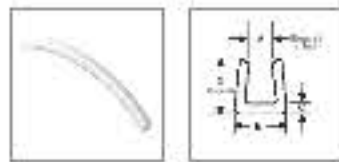

ROHS SUBMITTAL PACKAGE

**Where To Buy**

Enter Zip Code:

Enter Quantity:

**Features**

- Used to line panel edges and knockouts where the chafing of wires is a concern.
- Available in 8 stock sizes in 100-ft. lengths for panels from .040 - .250 inches thick and in a variety of stocked materials to cover a wide range of applications.

**General**

Style Extruded  
Material Nylon 6/6  
Color Black

**Dimension Information**

For Panel Thickness Max (inches) 0.052  
C (inches) 0.040  
D (inches) 0.190  
E (inches) 0.125

**Specifications**

Flammability Rating UL 94 V-2

**Tooling**

Application Tools SR-100

**Packaging**

Order Multiple 1  
Inner Package 1  
Outer Package 20  
Feet per Roll 100  
Package Height 12  
Package Length 18  
Package Width 12.5  
T&B Sold in UOM Each  
T&B Weight Per UOM 0.95 lbs. Each

**Certifications**

RoHS Compliance Yes [Generate Compliance Certificate](#)