



Long Barrel Copper Lug T&B Catalog Number:

256-30695-1252

UPC Number:

78621064226


Status:

Active

Description:

Copper One-Hole Lug, Long Barrel, Blind End, Max 35kV, Wire Size 4/0 AWG, 1/4 Inch Bolt Size, 1/4 Inch Hole Spacing, Tin Plated, Die Color Code Purple, Die Code 54

General

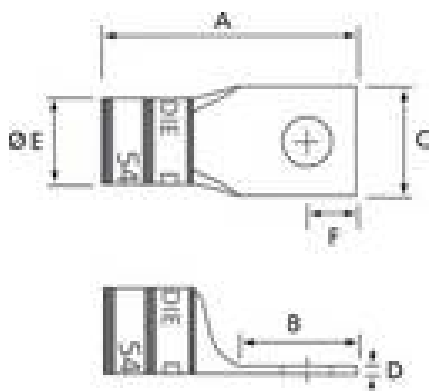

Material	Copper
Finish	Tin Plated
Wire Size	4/0 AWG
Number of Studs	1
Stud Size	1/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Purple
Die Code	54

Dimension Information

A (inches)	2.953
B (inches)	1.25
C (inches)	1.031
D (inches)	.141
E (inches)	.703
F (inches)	.25

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	10 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com