



Color-Keyed®



T&B Catalog Number:
UPC Number:
Description:

54104UF
 78621086834
 Copper One-Hole Lug - 45 degree Standard Barrel - max 35KV, #8 AWG Wire, #10 Bolt Size, Tin Plated with Inspection Hole, Red 21
 Active

Status:

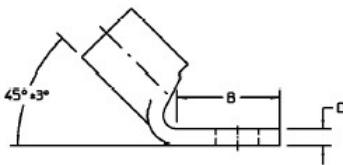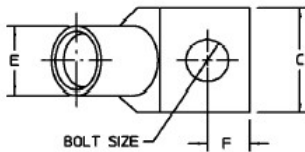

General

-Material	Copper
-Finish	Tin Plated
-Wire Size	#8 AWG
-Number of Studs	1
-Stud Size	#10
-Tongue Angle	45
-Barrel Length	Standard
-Barrel Shape	Standard
-Tongue Width	Standard
-Peep Hole	Y
-Marking	Standard
-Hole Shape	Round
-Die Color	Red
-Die Code	21

Dimension Information

-A (inches)	1.063
-B (inches)	0.469
-C (inches)	0.406
-D (inches)	0.078
-E (inches)	0.25
-F (inches)	0.219

Packaging

-T&B Order Multiple	50
-Package in Units	500
-T&B Sold in UOM	Each
-T&B Weight Per UOM	1.1 lbs. per 100

Application Support

-Overview	Available on Website
-Connector & Tooling Chart	Available on Website

Notes

-	Dimensions given for reference only. Dimensions may vary up to +/- .030.
---	--

Certifications

-RoHS Compliance	Yes
------------------	-----

Certifications



File Nbr:
 E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com