



Color-Keyed®

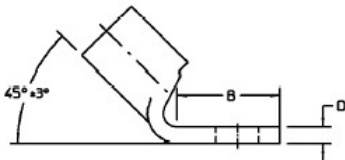

T&B Catalog Number: 54106UFB
UPC Number: 78621093093
Description: Copper One-Hole Lug - 45 degree Standard Barrel - max 35KV, #4 AWG Wire, 1/4" Bolt Size, Tin Plated with Inspection Hole, Bottom Stacking, Grey 29
Status: Active

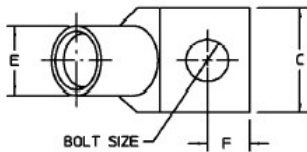

General

-Material	Copper
-Finish	Tin Plated
-Wire Size	#4 AWG
-Number of Studs	1
-Stud Size	1/4
-Tongue Angle	45
-Barrel Length	Standard
-Barrel Shape	Standard
-Tongue Width	Standard
-Peep Hole	Y
-Stacking	Bottom
-Marking	Standard
-Hole Shape	Round
-Die Color	Grey
-Die Code	29

Packaging

-T&B Inner Pack	50
-Package in Units	500
-T&B Sold in UOM	Each
-T&B Weight Per UOM	4 lbs. per 100

Application Support

-Overview	Available on Website
-Connector & Tooling Chart	Available on Website

Notes

- Dimensions given for reference only. Dimensions may vary up to -

Certifications

-RoHS Compliance	Yes
------------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email:techsupport@tnb.com