

Standard Barrel Copper Lug

T&B Catalog Number:

54112SP

UPC Number:


78621068249

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, 4/0 AWG Wire, 3/8" Bolt Size, Silver Plated with Inspection Hole, Purple 54

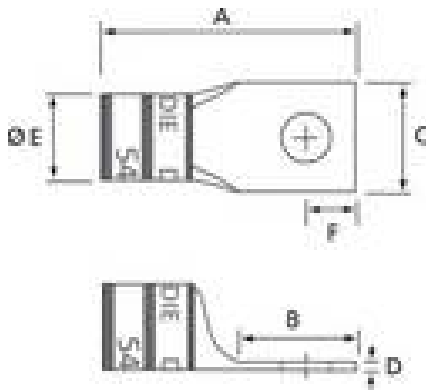

General

Material	Copper
Finish	Silver Plated
Wire Size	4/0 AWG
Number of Studs	1
Stud Size	3/8
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Purple
Die Code	54

Dimension Information

A (inches)	2.18
B (inches)	0.93
C (inches)	1.03
D (inches)	0.14
E (inches)	0.7
F (inches)	0.375

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	11.3 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com