

Standard Barrel Copper Lug

T&B Catalog Number:

54126

UPC Number:


78621054126

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, 900 kcmil Wire, 5/8" Bolt Size, Tin Plated with Inspection Hole, Yellow 115

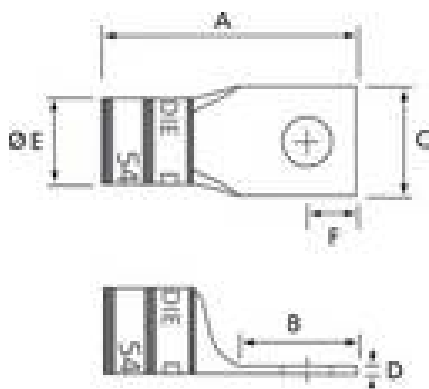

General

Material	Copper
Finish	Tin Plated
Wire Size	900 kcmil
Number of Studs	1
Stud Size	5/8
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	115

Dimension Information

A (inches)	4.15
B (inches)	1.58
C (inches)	2.17
D (inches)	0.31
E (inches)	1.50
F (inches)	5/8

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	3
T&B Inner Pack	3
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	90 lbs. per 100

Application Support

T&B Instruction Sheets	ta00884-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com