

Standard Barrel Copper Lug
T&B Catalog Number:

54131UF

UPC Number:



78621036165

Status:

Active

Description:

Copper One-Hole Lug - 45 degree Standard Barrel - max 35KV, #8 AWG Wire, 5/16" Bolt Size, Tin Plated with Inspection Hole, Red 21

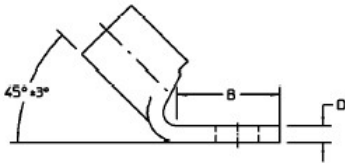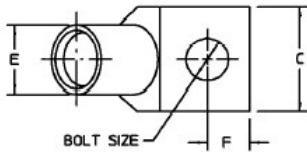

General

Material	Copper
Finish	Tin Plated
Wire Size	#8 AWG
Number of Studs	1
Stud Size	5/16
Tongue Angle	45
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Red
Die Code	21

Dimension Information

A (inches)	1.313
B (inches)	.719
C (inches)	.594
D (inches)	.031
E (inches)	.25
F (inches)	.344

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	15.63 lbs. per 1000

Application Support

T&B Instruction Sheets	ta00675-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com