

**Disconnects**  
**T&B Catalog Number:**

A18-111F

**UPC Number:**


78621080227

**Status:**

Active

**Description:**

Non-Insulated Female Disconnect, Length .59 Inches, Width .15 Inches, Tab Size .110x.020, Wire Range #22-#18 AWG, Copper, Tin Plated

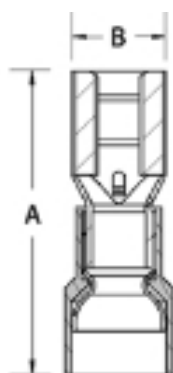

**General**

Disconnect Type	Female - 110 Series
Insulation Type	Non-Insulated
Terminal Series	A
Material	Brass
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	22-18
Tab Size	.110 x .020

**Dimension Information**

Stock Thickness	.03
A (inches)	.59
B (inches)	.15

**Specifications**

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

**Tooling**

Tool Charts	Available on Website
Recommended Tool	WT111M

**Packaging**

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.63 lbs. per 1000
Alternate Package Qty	A11

**Application Support**

Wire Guide Tables	Available on Website
-------------------	----------------------

**Certifications**

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email:techsupport@tnb.com