



**Anti-Rotational
T&B Catalog Number:**

ADR30AR
78378614982
Active

**UPC Number:
Status:
Description:**

Type ADR-ALCUL Anti-Rotational Single-Conductor, One-Hole Mount, Conductor Range Max 300 MCM, Min 6 AWG, 7/16 Inch Bolt Hole, Tin Plated

Features

Unique bottom rib keeps the conductor from turning. Eliminates the need for excessive torque, which can damage large conductors.
Bottom rib prevents conductor from loosening, even in heavy-vibration applications.

General

Style	Anti-Rotational ALCUL Single-Conductor, One-Hole Mount
Material	Aluminum
Plating	Tin-Plated
Conductor Range (AL or CU) Maximum	300 MCM
Conductor Range (AL or CU) Minimum	6 AWG

Dimension Information

A (inches)	2
B (inches)	1.000
C (inches)	1.12
D (inches)	.250
E (inches)	.2
F (inches)	.468
G (inches)	.094
H (inches)	1.00
M (inches)	.330
N (inches)	.656

Packaging

T&B Inner Pack	25
Package in Units	250
T&B Sold in UOM	Each
T&B Weight Per UOM	10.5 lbs. per 100

Notes

UL 486B tested, AL9CU rated

Certifications


RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

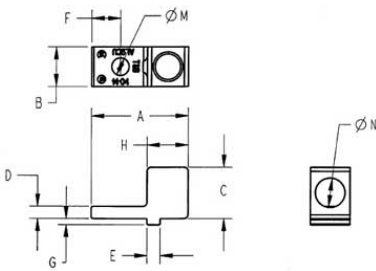

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com