



## Rectangle Ring Terminal T&B Catalog Number:

**UPC Number:** C483  
78621081127  
**Status:** Active  
**Description:**


Non-Insulated Rectangle Ring Terminal For Wire Range 12-10 Stud Size #5, Metallic, Military Specified (MIL-SPEC MS21004-16)

### WEB\_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

### Features

Funneled Barrel Entry, Deep Internal Serrations, Brazed or overlapping seams.

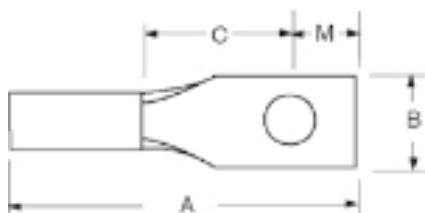

### General

Insulation Type	Non-Insulated
Terminal Series	C
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	12-10
Stud Size	#5
Bu-Ships Tongue Shape	L83

### Dimension Information

Stock Thickness	.04
A (inches)	.76
B (inches)	.28
C (inches)	.28
M (inches)	.14

### Specifications

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0
MIL Specification	MS-21004-16

### Tooling

Tool Charts	Available on Website
Application Tools	ERG4002
Recommended Tool	ERG4002, ERG4005

### Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.5 lbs. per 100

### Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

### Notes

12-10 ga. = 6-9 Navy

A, B, C483 for use with BU-Ships terminal board types 8TB.

## Certifications

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com