

**Flag Terminal**  
**T&B Catalog Number:**

D226  
 78621081164  
 Active

**UPC Number:**  
**Status:**  
**Description:**

Non-Insulated Flag Terminal, Length .90 Inches, Width .50 Inches, Bolt Hole #10, Wire Range #8 AWG, Copper, Tin Plated



**Features**


Flag terminals allow a 90 degree connection to the terminal block without bending the wire.

**General**

Insulation Type	Non-Insulated
Terminal Series	D
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	9, 8, 7
Stud Size	#10

**Dimension Information**

Stock Thickness	.06
A (inches)	.88
B (inches)	.50
C (inches)	.29
M (inches)	.64

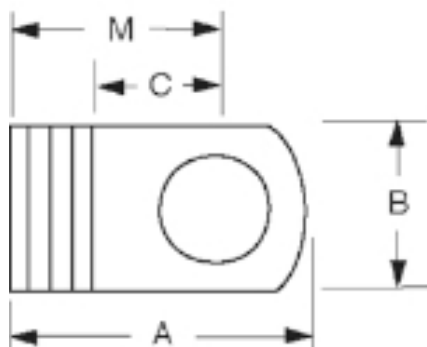

**Specifications**

Temperature Rating	150°C
Flammability Rating	UL 94 V-0

**Tooling**

Tool Charts	Available on Website
Application Tools	WT129, 13642M
Recommended Tool	WT129

**Packaging**

T&B Order Multiple	200
T&B Inner Pack	200
Package in Units	2000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	5 lbs. per 100

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

**Notes**

Not available on Mylar Tape.

**Certifications**

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)