

Flag Terminal
T&B Catalog Number:

E226
 78621081199
 Active

UPC Number:
Status:
Description:

Non-Insulated Flag Terminal, Length .93 Inches, Width .50 Inches, Bolt Hole #10, Wire Range #6 AWG, Copper, Nickel Plated



Features


Flag terminals allow a 90 degree connection to the terminal block without bending the wire.

General

Insulation Type	Non-Insulated
Terminal Series	E
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	6, 5
Stud Size	#10

Dimension Information

Stock Thickness	.06
A (inches)	.93
B (inches)	.50
C (inches)	.29
M (inches)	.69

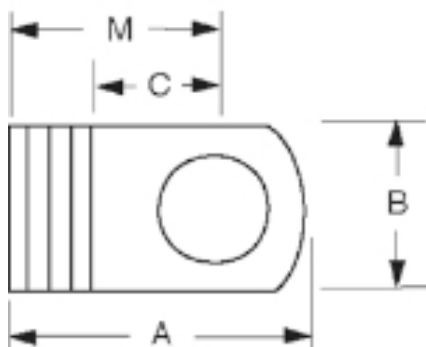

Specifications

Temperature Rating	150°C
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	WT129, 13642M
Recommended Tool	WT129

Packaging

T&B Order Multiple	200
T&B Inner Pack	200
Package in Units	2000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	6.25 lbs. per 1000

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Not available on Mylar Tape.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com