



Ferrule
T&B Catalog Number:

F2054
 78621033558
 Active

UPC Number:
Status:
Description:


Polypropylene-Insulated Ferrule, Total Length 1.614 Inches/41mm, Pin Length .984 Inches/25mm, Pin Diameter .413 Inches/10.5mm, Base Diameter .591 Inches/15.0mm, Wire Range 1/0 AWG/50.00mm², Color Blue, Copper, Tin Plated

WEB_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

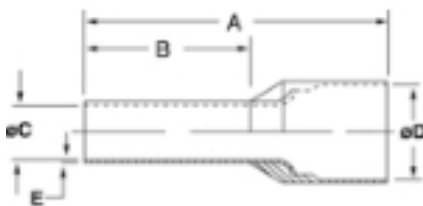

General

Ferrule Type	Insulated
Insulation Type	Polypropylene
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	1/0
Wire Size (mm ²)	50.00

Dimension Information

A (mm)	41.0
B (mm)	25.0
Diameter C (inches)	.413
Diameter C (mm)	10.5
Diameter D (inches)	.591
Diameter D (mm)	15.0
E (mm)	.35
A (inches)	1.614
B (inches)	.984
E (inches)	.014

Specifications

Temperature Rating	105°C
Flammability Rating	94HB

Tooling

Tool Charts	Available on Website
Application Tools	ERG4
Recommended Tool	ERG4

Packaging

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	1.25 lbs. per 1000

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com