

Flag Terminal
T&B Catalog Number:

F271
 78621081227
 Active

UPC Number:
Status:
Description:

Non-Insulated Flag Terminal, Length 1.10 Inches, Width .63 Inches, Bolt Hole 1/4 Inch, Wire Range #4 AWG, Copper, Nickel Plated



Features

Flag terminals allow a 90 degree connection to the terminal block without bending the wire.

General

Insulation Type	Non-Insulated
Terminal Series	F
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	4, 3
Stud Size	1/4

Dimension Information

Stock Thickness	.07
A (inches)	1.10
B (inches)	.63
C (inches)	.33
M (inches)	.80

Specifications

Temperature Rating	150°C
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	WT129, 13642M
Recommended Tool	WT129

Packaging

T&B Order Multiple	200
T&B Inner Pack	200
Package in Units	1000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	2.63 lbs. per 100

Application Support


Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Not available on Mylar Tape.

Certifications

RoHS Compliance	Yes
-----------------	-----

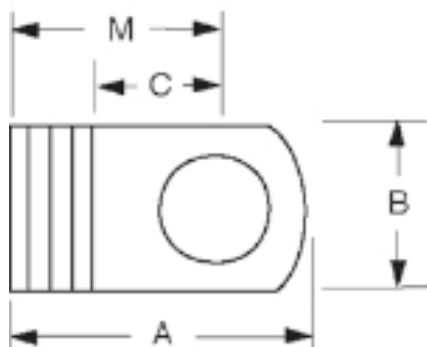

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com