



**Ferrule**  
**T&B Catalog Number:**


F4006  
 78621072964  
 Active

**UPC Number:**  
**Status:**  
**Description:**

Polypropylene-Insulated Ferrule, Total Length .416 Inches/10.5mm, Pin Length .236 Inches/6.0mm, Pin Diameter .031 Inches/.8mm, Base Diameter .079 Inches/2.0mm, Wire Range #24 AWG/.25mm<sup>2</sup>, Color Yellow, Copper, Tin Plated

**Features**

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

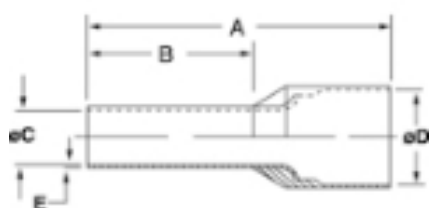

**General**

Ferrule Type	Insulated
Insulation Type	Polypropylene
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	24
Wire Size (mm <sup>2</sup> )	.25

**Dimension Information**

A (mm)	10.5
B (mm)	6.0
Diameter C (inches)	.031
Diameter C (mm)	0.8
Diameter D (inches)	.079
Diameter D (mm)	2.0
E (mm)	.25
A (inches)	.413
B (inches)	.236
E (inches)	.010

**Specifications**

Temperature Rating	105°C
Flammability Rating	94HB

**Tooling**

Tool Charts	Available on Website
Application Tools	T3, ERG4
Recommended Tool	T3, ERG4

**Packaging**

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	10000
T&B Sold in UOM	Each
T&B Weight Per UOM	0.63 lbs. per 1000

**Application Support**

T&B Sales Drawings	wsd-000402
Overview	Available on Website
Wire Guide Tables	Available on Website

## Notes

Ferrule dimensions conform to DIN 46228, Part 4.

## Certifications

RoHS Compliance	Yes
-----------------	-----

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)