



**Splice Connector**  
**T&B Catalog Number:**

H1/0-PS-C  
 78621089086  
 Active

**UPC Number:**  
**Status:**  
**Description:**


Non-Insulated Parallel Splice, Length .750 Inches, Outer Diameter .571 Inches, Inner Diameter .446 Inches, Wire Range 1/0 AWG, 83,700kcmi-119,500kcmil, Copper, Tin Plated

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Resistant to corrosion and preserve the electrical integrity of the wires in single or multiple strands. Feature an intelligent constructable part number for quick identification of the wire range.

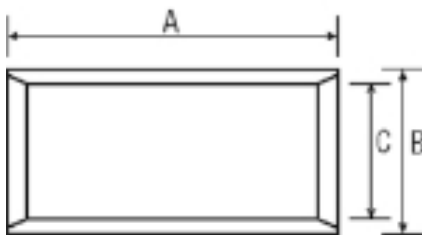

**General**

Insulation Type	Non-Insulated
Terminal Series	H
Material	Copper
Finish	Tin Plated
Color	Metallic
Wire Range	1/0

**Dimension Information**

A (inches)	.750
B (inches)	.571
C (inches)	.446

**Specifications**

Circular Mil Area	83,700-119,500
Voltage Rating	600V

**Tooling**

Tool Charts	Available on Website
Application Tools	TBM750M1, TBM8750BSCR
Recommended Tool	TBM8750M1

**Packaging**

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	1000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 100

**Application Support**

T&B Sales Drawings	wsd-000229
Overview	Available on Website
Wire Guide Tables	Available on Website

**Certifications**

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)