


T&B Conduit Fittings

Liquidtight Flexible Metal Conduit Fittings





Liquidtight Flexible Metal/MS Fittings

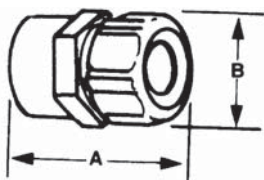

T&B Liquidtight flexible metal and Liquidtight flexible nonmetallic fittings with internal threads to accept AN-MS fitting shells.

Material: Steel

Cat. No.	Trade Size	AN-MS Conn. Shell Size	Internal Thread Thread Size	Dimensions (in.)	
				A	B
LTA03810	3/8	10SL, 12, 12S	5/8—24 UNEF-2B	1-5/32	1
LTA03814	3/8	14, 14S	3/4—20 UNEF-2B	1-5/32	1
LTA05014	1/2	14, 14S	3/4—20 UNEF-2B	1-5/16	1-1/4
LTA05016	1/2	16, 16S	7/8—20 UNEF-2B	1-5/16	1-1/4
LTA05018	1/2	18	1—20 UNEF-2B	1-5/16	1-1/4
LTA07516	3/4	16, 16S	7/8—20 UNEF-2B	1-7/16	1-1/2
LTA07518	3/4	18	1—20 UNEF-2B	1-7/16	1-1/2
LTA07520	3/4	20, 22	1-3/16—18 UNEF-2B	1-7/16	1-1/2
LTA10020	1	20, 22	1-3/16—18 UNEF-2B	1-3/4	1-23/32
LTA10024	1	25, 28	1-7/16—18 UNEF-2B	1-3/4	1-23/32

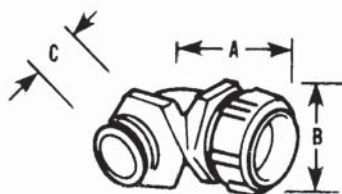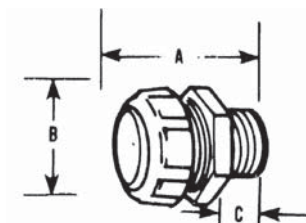

Fittings for Liquidtight flexible metal conduit with metric threads of PG Form (DIN 40430).

PG Metric Thread Liquidtight Fittings*



Cat. No.	Flexible Conduit Size	Metric PG Thread	Dimensions (mm)		
			A	B	C
Nylon insulated straight fittings					
7330**	1/4"	9	36	21	12
7360**	5/16"	9	36	26	12
7361*	3/8"	11	40	29	14
7362*	3/8"	13.5	40	29	14
7363*	1/2"	16	41	35	14
7364*	3/4"	21	43	42	14
7365	1"	29	56	47	19
7366	1-1/4"	36	67	58	21
7367	1-1/2"	42	72	69	21
7368	2"	48	81	83	21
Nylon insulated 45° angle fittings					
7341	3/8"	11	27	29	14
7342	3/8"	13.5	27	29	14
7343	1/2"	16	30	35	14
7344-TB	3/4"	21	34	42	14
7345	1"	29	44	47	19
7346	1-1/4"	36	51	58	19
7347	1-1/2"	42	60	69	21
7348-TB	2"	48	73	76	24
Nylon insulated 90° angle fittings					
7351	3/8"	11	37	29	14
7352	3/8"	13.5	37	29	14
7353	1/2"	16	40	35	14
7354	3/4"	21	44	42	14
7355	1"	29	56	47	21
7356	1-1/4"	36	70	58	21
7357	1-1/2"	42	75	69	21
7358	2"	48	87	83	24

U.L. Listed liquidtight.

*CSA Certified dusttight and watertight.

**U.L. not applicable and not CSA Certified.