


Protect It! 6-Outlet Surge Protector, 6 ft. Cord, 990 Joules, 2 USB Ports (2.1A), Black Housing

MODEL NUMBER: TLP606USBB

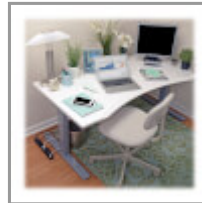

Safeguard your workstation or home electronics against surges, spikes and line noise. USB ports charge 2 mobile devices at the same time.

Description

Perfect for your home or office workstation, the TLP606USBB Protect It!® 6-Outlet Surge Protector features a surge suppression rating of 990 joules to defend your sensitive electronic components against strong surges and spikes.

The TLP606USBB includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression, as well as technology that filters out disruptive EMI/RFI line noise, preventing interference from disrupting your electronics and inflicting damage or data loss.

Your computer and peripherals plug into six NEMA 5-15R outlets, including one designed to accept bulky transformers without blocking adjacent outlets. Dual USB ports provide 2.1 total amps for fast charging smartphones, tablets, MP3 players and other portable devices. Integrated 15-amp circuit breaker protects all outlets against dangerous overloads. Lighted on/off switch provides one-touch control over connected equipment. Green LED indicates protection status.

The six-foot (1.8-meter) AC power cord with NEMA 5-15P plug allows the TLP606USBB to reach distant outlets, giving you flexibility in placing the surge protector. Keyhole slots incorporated into the bottom panel provide convenient wall or desk mounting options for the black plastic housing.

Features

990-Joule Surge Protection for Home or Office Electronics 990-joule rating protects your computer, printer, scanner, external hard drive and other sensitive electronic components against even the strongest surges and spikes
Backed by \$20,000 Ultimate Lifetime Insurance for any connected components damaged by power surge (U.S., Canada and Puerto Rico only)
Full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
Filters out disruptive EMI/RFI line noise that can cause equipment damage or data loss
Exceeds IEEE 587 Category A and B surge suppression specifications

6 Outlets Accept Wide Range of Electronic Devices 6 NEMA 5-15R AC outlets accept most computers and peripherals
Special end outlet designed for bulky transformers without blocking other outlets

Dual USB Ports Charge Mobile Devices USB ports offer up to 2.1A total of power capacity
Ideal for fast charging smartphones, tablets, MP3 players and other portable devices

Premium Safety Features Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required
Integrated 15A circuit breaker protects outlets against overloads
Green LED shows protection status at a glance

Fits Effortlessly Into Your Workstation 6 ft. AC power cord with NEMA 5-15P plug long enough to reach

Highlights

- 6 NEMA 5-15R outlets, including one for bulky transformers
- Surge suppression rating of 990 joules
- Filters out threatening EMI/RFI line noise
- 15A resettable circuit breaker prevents dangerous overloads
- 2 USB ports (2.1A total) for fast charging mobile devices

Package Includes

- TLP606USBB Protect It! 6-Outlet Surge Protector, Black Housing
- Owner's manual



Powering Business Worldwide

TRIPP LITE
SERIES

distant outletsKeyhole slots on bottom panel provide convenient wall or desk mounting optionsBlack plastic housing designed for long life

Auto-ShutdownAutomatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required

Specifications

OVERVIEW	
UPC Code	037332189851
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Maximum Surge Amps	35500
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT
Input Cord Length (ft.)	6
Right-Angle Plug	No
Input Cord Length (m)	1.83
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	50 / 60 Hz
Output (Watts)	1800
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Overload Protection	15A resettable illuminated combo switch / circuit breaker
Transformer Accommodation	(2) Yes
Outlet Orientation	Single row of 6 outlets
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	



Powering Business Worldwide

TRIPP LITE
SERIES

Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2 position red illuminated on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status
CHARGING	
Number of Charging Ports	2
Total Charging Watts	10.5
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 2.1A
Overcharge Protection	No
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	990
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	400V
EMI / RFI Filtering	Yes
Automatic Shut-Off	Yes
DATALINE SURGE SUPPRESSION	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
PHYSICAL	
Material of Construction	Plastic
Power Cord Color	Black
Housing Color	Black
Mounting Holes or Slots	Yes
Outlets Measurement (Center to Center)	28.5mm
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	1.90 x 5.70 x 14.70
Shipping Dimensions (hwd / cm)	4.83 x 14.48 x 37.34
Shipping Weight (lbs.)	1.30
Shipping Weight (kg)	0.59
Unit Dimensions (hwd / in.)	1.250 x 1.870 x 13.000



Powering Business Worldwide

TRIPP LITE
SERIES

Unit Dimensions (hwd / cm)	3.18 x 4.75 x 33.02
Unit Weight (lbs.)	1.05
Unit Weight (kg)	0.48
FEATURES & SPECIFICATIONS	
Rotatable Outlets	No
Antimicrobial	No
GaN Technology	No
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); cUL Listed; UL 1449; UL 1363; UL Listed
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$20,000 Ultimate Lifetime Insurance

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.