

Specification Sheet


Part Number: 184-13006

Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.

Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.

Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.

Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.

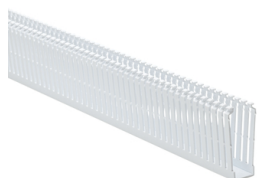

Article Number	184-13006
Type	SLHD1X3
Color	White (WH)
Quantity Per	pack
Product Description	HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.
Short Description	High Density Slotted Wall Wiring Duct, 1" x 3", Non-Adhesive, PVC, White, 30ft/Box

Global Part Name SLHD1X3-PVC-WH

Length L (Imperial) 6.0

Length L (Metric) 1.83

Width W (Imperial) 1.0

Width W (Metric) 25.4

Height H (Imperial) 3.07

Height H (Metric) 77.9

Mounting Hole Centers (Imperial) 2.0

Material Polyvinylchloride (PVC)

Material Shortcut PVC

Halogen Free No

UV Resistant (Yes/No) No

Operating Temperature +122°F (+50°C)

Reach Compliant (Article 33) No

ROHS Compliant Yes

Certification/Specification UL EN 50085-2-3_1A CSA EN 50085-1:2005 + A1:2013

UL Recognized (US) Yes

Package Quantity (Imperial) 30.0

Package Quantity (Metric) 9.14

Customs Number 3925900000

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)