


Specification Sheet

Part Number: CTM210C2

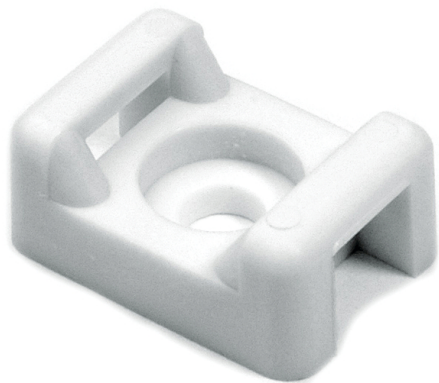

KR/CTM series are designed to provide stability to wire bundles.

These mounts can accommodate miniature, intermediate, or standard cross-section cable ties.

Each mount is secured with a single screw.

Article Number 151-30504

Type CTM2

Color White (WH)

Quantity Per pack

Product Description Designed specifically for holding heavier cable bundles these mounting bases can be used in many industries from agriculture to truck manufacture. They offer a very secure fixing and can be used with a wide variety of heavy duty cable ties up to 8.3 mm width.

Short Description Cable Tie Anchor Mount, 0.86 x .61", 0.18" Hole Dia, 0.31" Max Tie Width, PA66, White, 100/pkg

Global Part Name CTM2-PA66-WH

Length L (Imperial)	0.86
Length L (Metric)	21.8
Fixation Method	Screw Mount
Width W (Imperial)	0.61
Width W (Metric)	15.5
Cable Ties	T18 - T120
Height H (Imperial)	0.37
Height H (Metric)	9.40
Cable Tie Width Max (Imperial)	0.31
Cable Tie Width Max (Metric)	7.9
Mounting Hole Diameter D (Imperial)	0.18 "
Mounting Hole Diameter D (Metric)	4.6 mm
Mounting Hole Diameter D Max (Metric)	4.6
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66

Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL ANSI/UL 62275 UL ANSI/UL 1565 UL ANSI/UL 746B
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)