


## Specification Sheet

Part Number: FC1.2AK2

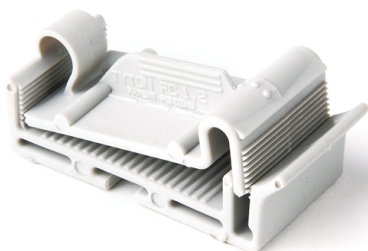

Adjustable height feature allows the clamp to close to the exact height of the ribbon cable.

Releasable for easy access to cables when necessary.

Flat Ribbon Cable Clamp, Adhesive, 1.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 50/pkg

Article Number 154-00013

Type FC1.2A

Color Gray (GY)

Quantity Per pack

Product Description HellermannTyton's flat ribbon clamps route, protect, and secure flat ribbon cables without damage to sensitive wires and cables. The unique, adjustable height feature allows the clamp to close to the exact height of the ribbon cable, using only as much force as needed to secure the cable. The releasable feature allows simple opening when access to the cable is necessary.

Short Description Flat Ribbon Cable Clamp, Adhesive, 1.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 50/pkg

Global Part Name	FC1.2A-PA66-GY
Length L (Imperial)	0.81
Length L (Metric)	20.57
Fixation Method	Adhesive
Width W (Imperial)	1.5
Width W (Metric)	38.1
Height H (Imperial)	0.5
Height H (Metric)	12.7
Cable Tie Width Max (Imperial)	1.2
Cable Tie Width Max (Metric)	30.48
Mounting Hole Diameter D (Imperial)	0.157 "
Mounting Hole Diameter D (Metric)	4.0 mm
Mounting Hole Diameter D Max (Metric)	4.0
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66

Adhesive	Acrylate with base of polyurethane foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Adhesive Operating Temperature	to +230°F (+110°C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)