


Specification Sheet

Part Number: FC1.2K2

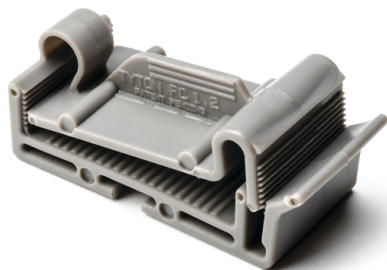

Adjustable-height feature allows the clamp to close to the exact height of the ribbon cable.

Releasable for easy access to cables when necessary.

Flat Ribbon Clamp, 1.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 50/pkg

Article Number 154-00011

Type FC1.2

Color Gray (GY)

Quantity Per pack

Product Description
HellermannTyton's flat ribbon clamps route, protect and secure flat ribbon cables without damage to sensitive wires and cables. The unique, adjustable height feature allows the clamp to close to the exact height of the ribbon cable, using only as much force as needed to secure the cable. The releasable feature allows simple opening when access to the cable is necessary.

Short Description
Flat Ribbon Clamp, 1.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 50/pkg

Global Part Name	FC1.2-PA66-GY
Length L (Imperial)	1.5
Length L (Metric)	38.1
Width W (Imperial)	2.5
Width W (Metric)	63.5
Height H (Imperial)	0.51
Height H (Metric)	12.95
Mounting Hole Diameter D (Imperial)	0.156 "
Mounting Hole Diameter D (Metric)	4.0 mm
Mounting Hole Diameter D Max (Metric)	4.0
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only

Operating Temperature -40°F to +185°F (-40°C to +85°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 50

Package Quantity (Metric) 50

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)