

Specification Sheet

Part Number: MB2.5A10C2


For use with HellermannTyton T18 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The rubber-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 0.3 lb.

Four predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

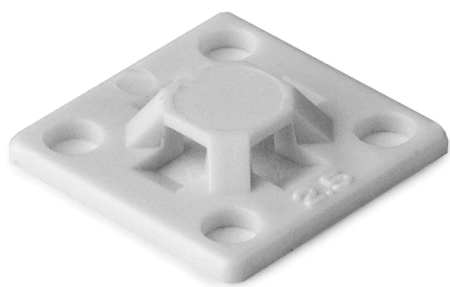

Rubber Adhesive Cable Tie Mount, 0.63 x 0.63", Use With T18 Cable Tie, PA66, White, 100/pkg

Article Number 151-29002

Type MB2.5A

Color White (WH)

Quantity Per pack

Product Description MB2.5 adhesive mounts are for use with HellermannTyton T18 Series cable ties to provide stability when securing bundles. The rubber adhesive-backed mounts can be used to secure a bundle and have four predrilled holes to extend mounting options.

Short Description	Rubber Adhesive Cable Tie Mount, 0.63 x 0.63", Use With T18 Cable Tie, PA66, White, 100/pkg
Global Part Name	MB2.5A-PA66-WH
Length L (Imperial)	0.63
Length L (Metric)	15.9
Fixation Method	Adhesive
Width W (Imperial)	0.63
Width W (Metric)	15.9
Cable Ties	T18
Height H (Imperial)	.16
Height H (Metric)	4.1
Cable Tie Width Max (Imperial)	0.1
Cable Tie Width Max (Metric)	2.54
Mounting Hole Diameter D (Imperial)	0.11 "
Mounting Hole Diameter D (Metric)	2.8 mm

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Adhesive	Synthetic rubber with base of polyethylene foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Adhesive Operating Temperature	0°F to +150°F (-18 °C to +66 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)