


Specification Sheet

Part Number: MB29M4

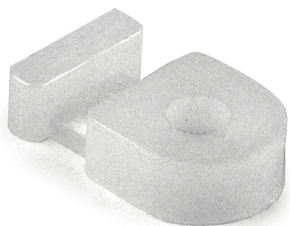

Compact size for areas with limited mounting space.

Simple to install with a screw or rivet.

Single hole attachment with two-way entry for cable tie.

Cable Tie Anchor Mount, 0.81 x .49", 0.193" Hole Dia, 0.18" Max Tie Width, PA66, Natural, 1000/pkg

Article Number 151-00297

Type MB2

Color Natural (NA)

Quantity Per pack

Product Description These cable tie mounts are compact in size. They are designed for simple yet robust installation particularly in areas with limited space. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets.

Short Description Cable Tie Anchor Mount, 0.81 x .49", 0.193" Hole Dia, 0.18" Max Tie Width, PA66, Natural, 1000/pkg

Global Part Name MB2-PA66-NA

Length L (Imperial)	0.81
Length L (Metric)	20.6
Fixation Method	Screw Mount
Width W (Imperial)	0.49
Width W (Metric)	12.5
Cable Ties	T18 - T50
Height H (Imperial)	.13
Height H (Metric)	3.30
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.193 "
Mounting Hole Diameter D (Metric)	4.9 mm
Mounting Hole Diameter D Max (Metric)	4.9
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66

Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	1000
Package Quantity (Metric)	1000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)