





4308H Series 5mm (T-1 3/4) Through Hole LED Solid State

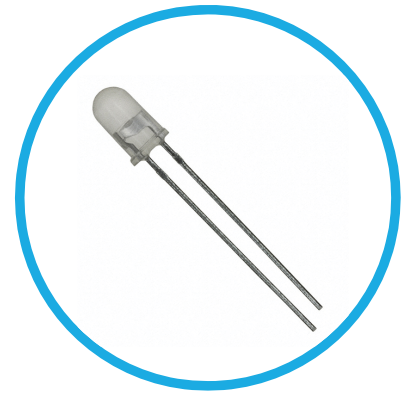

5mm Non-Diffused Clear LED Through Hole

Colors: Red or Yellow

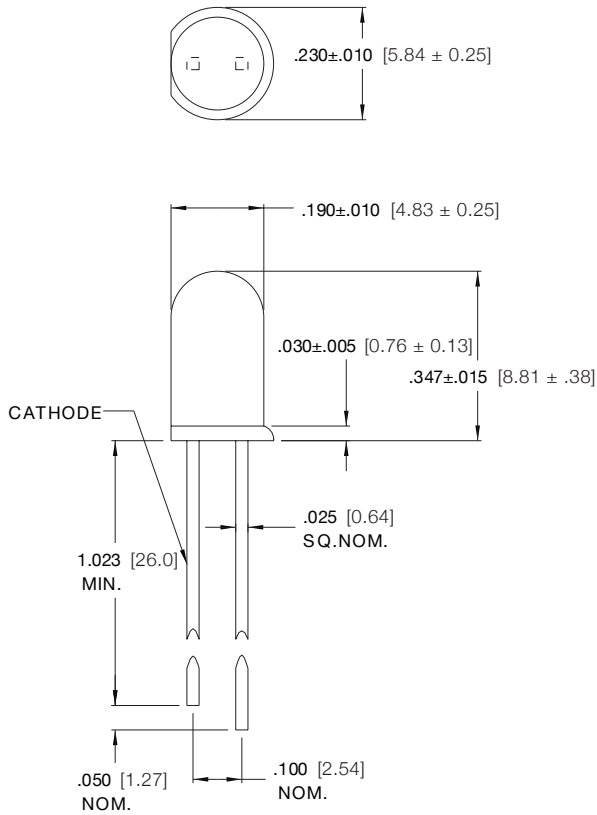

All dimensions are in inches [mm]

Electro-Optical Characteristics and Ratings

Part Number	4308H1	4308H7
Output Color	Red	Yellow
Diffusion	Non-Diffused	Non-Diffused
Package Color	Clear	Clear
Test Current (mA)	20	20
Forward Voltage Typ. (V)	1.8	2.1
Forward Voltage Max. (V)	2.2	2.6
Luminous Intensity Min. (mcd)	90	96
Luminous Intensity Typ. (mcd)	240	140
Peak Wavelength (nm)	645	583
Viewing Angle 20 1/2 (degrees)	24	24
Power Dissipation (mW)	87	-
Peak Forward Current max (mA)	300	60

Compliances and Approvals

