


Item no.: 231-105/026-000  
Product description: FEMALE PLUG; 5 POLE; PIN SPACING 5 MM / 0.197 IN;  
WITH CODIG FINGERS; WITH INTEGRATED FIXING  
FLANGES; CAGE CLAMP®CONNECTION

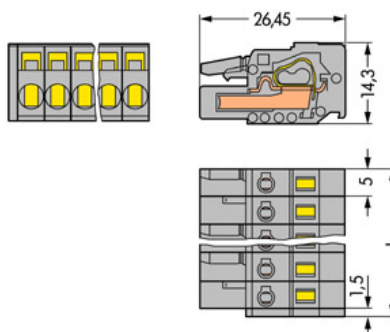

Packing unit 100 pieces

|                          |                        |
|--------------------------|------------------------|
| Product group            | 3 (Multi Conn. System) |
| Pin spacing from         | 5 mm                   |
| Pin spacing from         | 0,197 in               |
| pole count               | 5                      |
| Cross section from [mm²] | 0,08 mm²               |
| Cross section to [mm²]   | 2,5 mm²                |
| Cross section from [AWG] | 28 AWG                 |
| Cross section to [AWG]   | 12 AWG                 |
| Connection method        | CAGE CLAMP®CONNECTION  |
| Measured voltage EN      | 250 V                  |
| Measured shock voltage   | 4 kV                   |
| Pollution degree         | 3                      |
| Current intensity EN     | 16 A                   |
| Weight                   | 9,16 g                 |
| Color                    | grey                   |
| No. of connection Points | 5                      |
| No. of potentials        | 5                      |
| Height                   | 14,3 mm                |
| Height                   | 0,563 in               |
| Width                    | 26,5 mm                |
| Width                    | 1,043 in               |
| Depth                    | 26,45 mm               |



|                   |          |
|-------------------|----------|
| Depth             | 1,041 in |
| Strip length from | 8 mm     |
| Strip length to   | 9 mm     |
| Strip length      | 0,33 in  |



| Item number     | Admission office | Approval no.    | Voltage [V] | Current [A] | Cross section [ mm² ] |
|-----------------|------------------|-----------------|-------------|-------------|-----------------------|
| 231-105/026-000 | ABS              | 04-HG469925-PDA | 400         | 16          | 5,0                   |
| 231-105/026-000 | BV               | 11915/A0        | 400         | 16          | 2,5                   |
| 231-105/026-000 | CCA              | 5764            | 250         | 16          | 0,08-2,5              |
| 231-105/026-000 | CSA              | 154112-1466354  | 300         | 15          | 22-12                 |
| 231-105/026-000 | DEMKO            | 88126           | 250         | 16          | 2,5                   |
| 231-105/026-000 | GL               | 17296-00HH      | 400         | 16          | 5,0                   |
| 231-105/026-000 | KEMA             | 2083746.02      | 250         | 16          | 0,08-2,5              |
| 231-105/026-000 | KR               | HMB05880-EL003  | 250/400     | 12/16       | 2,5                   |
| 231-105/026-000 | LR               | 96/20035        | 400         | 16          | 5,0                   |
| 231-105/026-000 | RMR              | 11130002        | 400         | 16          | 5,0                   |
| 231-105/026-000 | UR               | E45171          | 600         | 15          | 12                    |
| 231-105/026-000 | UR               | E45172          | 300         | 15          | 22-12                 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected