


Item no.: 231-110/031-000
 Product description: FEMALE CONNECTOR WITH FIXING FLANGE 10 POLE PIN SPACING 5 MM / 0.197 IN WITH CODING FINGERS WITH INTEGRATED FIXING FLANGES FOR PANEL MOUNTING FOR SCREW OR SIMILAR MOUNTING TYPES

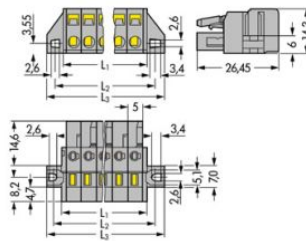

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	18.85 g
Color	gray
No. of connection Points	10
No. of potentials	10
pole count	10
Height	14.3 mm
Height	0.563 in
Width	64.8 mm
Width	2.551 in
Depth	26.45 mm
Depth	1.041 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV

Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/035-000	Strain relief plate 50 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-110/031-000	ABS	04-HG469925/1-PDA	400	16	5,0
231-110/031-000	BV	11915/A0	400	16	2,5
231-110/031-000	CCA	5764	250	16	0,08-2,5
231-110/031-000	CSA	154112-1466354	300	15	22-12
231-110/031-000	GL	17296-00HH	400	16	5,0
231-110/031-000	KEMA	2083746.02	250	16	0,08-2,5
231-110/031-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-110/031-000	LR	91/20112(E3)	400	16	5,0
231-110/031-000	RMR	11130002	400	16	5,0
231-110/031-000	UR	E45171	600	15	28-12
231-110/031-000	UR	E45172	300	15	22-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected