


Item no.: 232-166  
 Product description: FEMALE PLUG; WITH STRAIGHT SOLDER PIN; 6 POLE; PIN SPACING 5.08 MM / 0.2 IN; SOLDER PIN 0.6x1 MM; WITH CODIG FINGERS

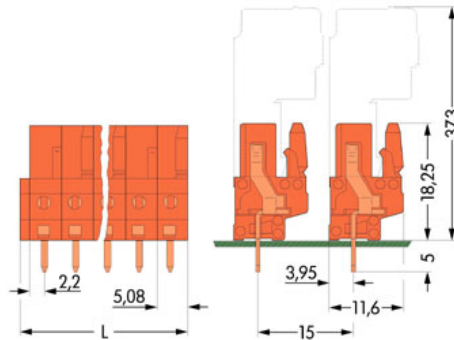

Packing unit 50 pieces

Product group	3 (Multi Conn. System)
Pin spacing from	5,08 mm
Pin spacing from	0,2 in
pole count	6
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	12 A
Weight	5,45 g
Color	orange
No. of connection Points	6
No. of potentials	6
Height	18,25 mm
Height	0,719 in
Width	31,98 mm
Width	1,259 in
Depth	11,6 mm
Depth	0,457 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
232-166	ABS	04-HG469925-PDA	250	12	0,8-2,5
232-166	BV	11915/A0	400	16	2,5
232-166	CCA	5764	250	12	0,6x1
232-166	CSA	154112-1466354	300	15	0,6x1
232-166	DEMKO	88126	250		2,5
232-166	GL	17296-00HH	250	12	0,8-2,5
232-166	KEMA	2083746.02	250	12	0,6x1
232-166	KR	HMB05880-EL003	250/400	12/16	2,5
232-166	LR	96/20035	250	12	0,8-2,5
232-166	NEMKO	P94101840	250		2,5
232-166	RMR	11130002	250	12	0,8-2,5
232-166	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected