
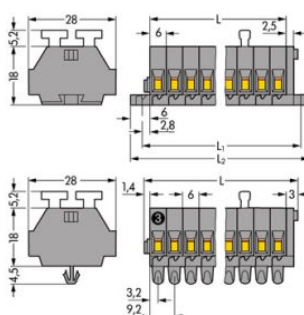


Item no.: 261-104/331-000
 Product description: 2-CONDUCTOR TERMINAL STRIP PUSH BUTTONS ON ONE SIDE WITH FIXING FLANGE FOR SCREW OR SIMILAR MOUNTING TYPES 3.2 MM Ø MOUNTING ADAPTER AVAILABLE FOR TS 35 (209-123) 4 POLE

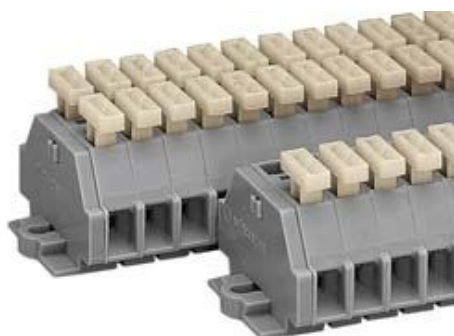

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	9 (Std Chassis Mt Blocks)
pole count	4
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [AWG]	28 - 14 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	24 A
Weight	11.35 g
Color	gray
Wiring type	Side-entry
No. of connection Points	8
No. of potentials	4
Height	23.2 mm
Height	0.914 in
Width	38.5 mm

Width	1.516 in
Depth	28 mm
Depth	1.103 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in
xxx-xxx/000-006	blue

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected