




Color: ■ gray

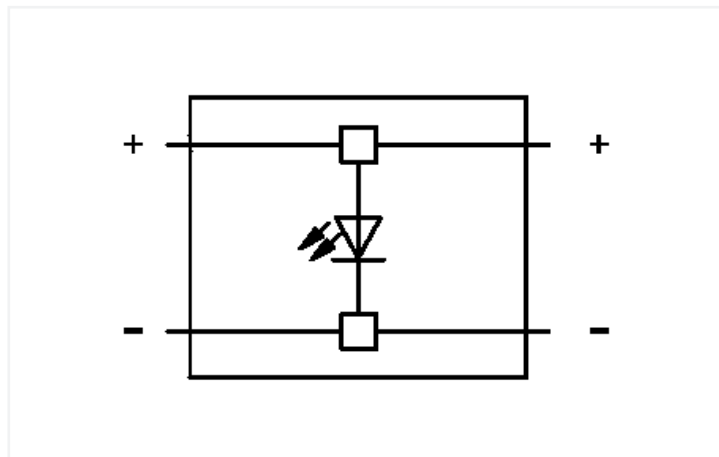

280-803/281-413

### Electrical data

#### Ratings per IEC/EN

Rated current	0.025 A
Operation status indicator	24 V

#### General

Voltage type 1	DC
----------------	----

### Connection data

#### Connection 1

Actuation type	Operating tool
----------------	----------------

### Physical data

Width	10 mm / 0.394 inches
-------	----------------------

### Material Data

Note (material data)

[Information on material specifications can be found here](#)

Color	gray
Material group	I
Insulation material	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.128 MJ
Weight	4.2 g

### Environmental requirements

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C

### Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
eCl@ss 10.0	27-14-11-49
eCl@ss 9.0	27-14-11-49
ETIM 8.0	EC002018
ETIM 7.0	EC002018
PU (SPU)	50 pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454396602
Customs tariff number	85366990990

### Downloads

#### Environmental Product Compliance

##### Compliance Search

Environmental Product  
Compliance  
280-803/281-413





### Documentation

#### Additional Information

Technical Section pdf  
2142.18 KB



#### Bid Text

280-803/281-413	19.02.2019	xml 2.69 KB	
280-803/281-413	27.04.2017	doc 23.00 KB	

### CAD/CAE-Data

#### CAD data

2D/3D Models  
280-803/281-413



#### CAE data

WSCAD Universe  
280-803/281-413



ZUKEN Portal  
280-803/281-413

