


## Data Sheet | Item Number: 289-708

Interface module; HD-Sub-D; Female connector; 62-pole; Triple-deck PCB terminal blocks; in mounting carrier; with shield connection; 2,50 mm<sup>2</sup>

<https://www.wago.com/289-708>

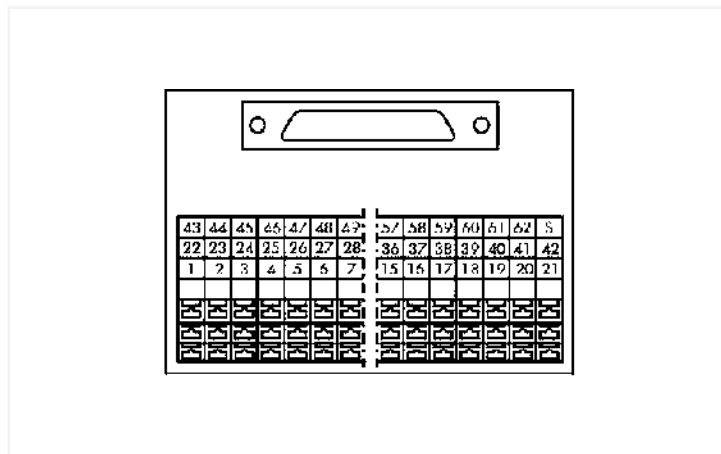

### Electrical data

Operating voltage	≤ AC/DC 125 V
Nominal current	1 A
Contact resistance (max.)	15 mΩ
Specialty functions	With shield connection

### Safety and protection

Rated voltage	125 V
Rated surge voltage	0.8 kV
Pollution degree	2
Protection type	IP20

### Connection data

Performance level	3 / 50 mating cycles
Strain relief	UNC 4-40 stud bolt

#### Connection 1

Connector	HD D-sub female connector
Pole number 1	62
Connection type 1	System
Note (conductor cross-section)	12 AWG: THHN, THWN
Mating direction	vertical
Connection type	Female connector; D-sub/HD D-sub

#### Connection 2

Design 2	PCB terminal blocks (triple-deck)
Pole number 2	63
Connection type 2	Field
Connection technology 2	CAGE CLAMP®
WAGO connector 2	WAGO 737 Series
Solid conductor 2	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor 2	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Strip length 2	5 ... 6 mm / 0.2 ... 0.24 inches

### Physical data

Width	108 mm / 4.252 inches
Height	85 mm / 3.346 inches
Depth from upper-edge of DIN-rail	62 mm / 2.441 inches

### Mechanical Data

Mounting type	DIN-35 rail
Housing design	Mounting carrier

### Material Data

Contact material (connector)	Au over Ni
Fire load	1.184 MJ
Weight	172.5 g

### Environmental requirements

Ambient temperature (operation at $U_N$ )	-20 ... +55 °C
Surrounding air temperature (storage)	-40 ... +70 °C
Relative humidity	≤ 85% (non-condensing)
Operating altitude (max.)	2000 m

### Standards and specifications

Standards/specifications	EN 61010-2-201
--------------------------	----------------

### Commercial data

Product Group	6 (INTERFACE ELECTRONIC)
eCl@ss 10.0	27-14-11-52
eCl@ss 9.0	27-14-11-52
ETIM 8.0	EC002780
ETIM 7.0	EC002780
PU (SPU)	4 (1) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454344290
Customs tariff number	8536690990