


---

|                      |                                                                                                                                                                                                                               |
|----------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Item no.:            | 721-604/019-000                                                                                                                                                                                                               |
| Product description: | MALE CONNECTOR WITH FIXING FLANGE 4 POLE PIN<br>SPACING 5 MM / 0.197 IN 100% PROTECTED AGAINST<br>MISMATING WITHOUT PRECEDING GROUND CONTACT<br>FOR SCREW OR SIMILAR MOUNTING TYPES FOR<br>PARALLEL OR PERPENDICULAR MOUNTING |

---

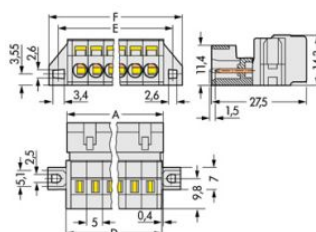

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

|                          |                        |
|--------------------------|------------------------|
| Product group            | 3 (Multi Conn. System) |
| Weight                   | 7.32 g                 |
| Color                    | light gray             |
| No. of connection Points | 4                      |
| No. of potentials        | 4                      |
| pole count               | 4                      |
| Height                   | 14.3 mm                |
| Height                   | 0.563 in               |
| Width                    | 34.8 mm                |
| Width                    | 1.37 in                |
| Depth                    | 27.5 mm                |
| Depth                    | 1.083 in               |
| Pin spacing from         | 5 mm                   |
| Pin spacing from         | 0.197 in               |
| Pollution degree         | 2                      |
| Measured voltage EN      | 320 V                  |

|                        |       |
|------------------------|-------|
| Measured shock voltage | 4 kV  |
| Current intensity EN   | 12 A  |
| Pollution degree       | 2     |
| Measured voltage EN    | 630 V |
| Measured shock voltage | 4 kV  |
| Current intensity EN   | 12 A  |



|                     |                           |
|---------------------|---------------------------|
| Connection method   | CAGE CLAMP® CONNECTION    |
| Cross section [mm²] | 0.08 - 2.5 mm²            |
| Wiring method       | solid                     |
| Cross section [mm²] | 0.08 - 2.5 mm²            |
| Cross section [mm²] | 0.25 - 1.5 mm²            |
| Cross section [mm²] | 0.25 - 2.5 mm²            |
| Cross section [AWG] | 28 - 12 AWG               |
| Strip length from   | 8 mm                      |
| Strip length to     | 9 mm                      |
| Material group      | I                         |
| xxx-xxx/033-000     | Strain relief plate 20 mm |



| Item no.        | Admission office | Approval no.      | Voltage [V] | Current [A] | Cross section [ mm² ] |
|-----------------|------------------|-------------------|-------------|-------------|-----------------------|
| 721-604/019-000 | ABS              | 04-HG469925/1-PDA | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | BV               | 11915/A0          | 250         | 12          |                       |
| 721-604/019-000 | CCA              | 5764              | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | CSA              | 154112-1466354    | 300         | 15          | 28-12                 |
| 721-604/019-000 | DNV              | E-9218            | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | GL               | 17296-00HH        | 250         | 12          |                       |
| 721-604/019-000 | KEMA             | 2083746.02        | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | KR               | HMB05880-EL003    | 250/400     | 12/16       | 2,5                   |
| 721-604/019-000 | LR               | 96/20035          | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | RMR              | 11130002          | 250         | 12          | 0,08-2,5              |
| 721-604/019-000 | UR               | E45171            | 600         | 20          | 12                    |
| 721-604/019-000 | UR               | E45172            | 300         | 15          | 28-12                 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected