


Item no.: 733-335
 Product description: HEADER; STRAIGHT SOLDER PIN 0.8x0.8 MM; 5 POLE; PIN SPACING 2.5 MM / 0.098 IN; 100% PROTECTED AGAINST MISMATING; MATING DIRECTION PERPENDICULAR TO PCB

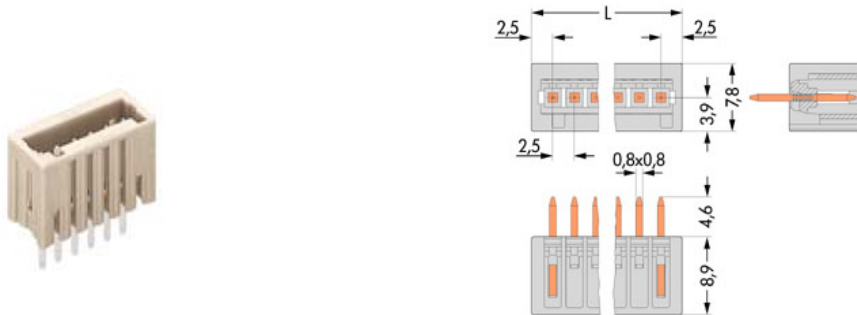

Packing unit 200 pieces

| | |
|------------------------|------------------------|
| Product group | 3 (Multi Conn. System) |
| Pin spacing from | 2,5 mm |
| Pin spacing from | 0,098 in |
| pole count | 5 |
| Measured voltage EN | 250 V |
| Measured shock voltage | 2,5 kV |
| Pollution degree | 2 |
| Current intensity EN | 4 A |
| Weight | 0,76 g |
| Color | light grey |
| Height | 8,9 mm |
| Height | 0,35 in |
| Width | 15 mm |
| Width | 0,591 in |
| Depth | 7,8 mm |
| Depth | 0,307 in |



| Item number | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|-------------|------------------|-----------------|-------------|-------------|-----------------------------------|
| 733-335 | ABS | 04-HG469925-PDA | 250 | 4 | |
| 733-335 | BV | 11915/A0 | 250 | 4 | |
| 733-335 | CCA | NL5640 | 250 | 4 | |
| 733-335 | CSA | 154112-1465035 | 150 | 4 | 28-20 |
| 733-335 | DNV | E-6997 | 250 | 4 | |
| 733-335 | GL | 17296-00HH | 250 | 4 | |
| 733-335 | KEMA | 2077592.01 | 250 | 4 | |
| 733-335 | LR | 96/20035 | 250 | 6 | |
| 733-335 | RMR | 11130002 | 250 | 4 | |
| 733-335 | UR | E45171 | 250 | 4 | |
| 733-335 | UR | E45172 | 150 | 4 | 28-20 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected