


Item no.: 232-262
 Product description: FEMALE CONNECTOR WITH RIGHT ANGLED SOLDER PIN
 2 POLE PIN SPACING 5.08 MM / 0.2 IN SOLDER PIN 0.6x1
 MM WITH CODING FINGERS MATING DIRECTION
 PARALLEL TO PCB CLOSED END

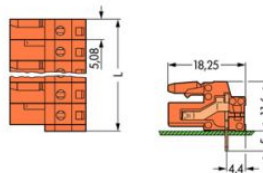

Produkt kann von Bild abweichen / product may differ

Packing unit 200 4*50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	1.9 g
Color	orange
No. of connection Points	2
No. of potentials	2
pole count	2
Height	11.6 mm
Height	0.457 in
Width	11.66 mm
Width	0.459 in
Depth	18.25 mm
Depth	0.719 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV

Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I
xxx-xxx/031-000	with fixing flange
xxx-xxx/039-000	with locking devices
xxx-xxx/047-000	with spacers



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
232-262	BV	11915/A0	400	16	2,5
232-262	CSA	154112-1466354	300	15	0,6x1
232-262	KR	HMB05880-EL003	250/400	12/16	2,5
232-262	UR	E45171	600	15	
232-262	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected