


Item no.: 745-202
 Product description: PCB TERMINAL STRIP 2 SOLDER PINS / POLE 2 POLE PIN
 SPACING 10 MM / 0.394 IN WITHOUT FIXING FLANGE

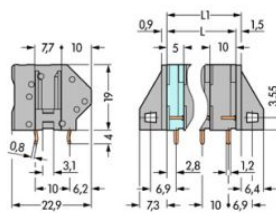

Produkt kann von Bild abweichen / product may differ

Packing unit 120 pieces

Product group	4 (Printed Circuit)
Weight	5.412 g
Color	gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	19 mm
Height	0.748 in
Width	16.5 mm
Width	0.65 in
Depth	22.9 mm
Depth	0.902 in
Pin spacing from	10 mm
Pin spacing from	0.394 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	32 A
Pollution degree	2
Measured voltage EN	1000 V

Measured shock voltage
Current intensity EN

8 kV
32 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm²]	0.08 - 4 mm²
Wiring method	solid
Cross section [mm²]	0.08 - 4 mm²
Cross section [mm²]	0.25 - 2.5 mm²
Cross section [mm²]	0.25 - 2.5 mm²
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/000-006	blue
xxx-xxx/000-009	light gray
xxx-xxx/000-016	green-yellow
xxx-xxx/000-017	light green
xxx-xxx/005-000	with fixing flange
xxx-xxx/005-xxx	with fixing flange



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
745-202	CCA	NL5831	250	32	0,08-4
745-202	cURus	E45172	300	20	28-12
745-202	KEMA	2076500.01	250	32	0,08-4

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected