

## SAIL-M8BG-4S1.5UIE

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The most reliable way of achieving connections between two I/O slaves or between the control and one I/O subscriber is by way of pre-assembled cables. The line of cables covers PROFIBUS, CANopen, DeviceNet™, EtherCAT and Ethernet.

### General ordering data

Type	SAIL-M8BG-4S1.5UIE
Order No.	<a href="#">1301370150</a>
Version	Bus line, One end without connector, M8, No. of poles: 4, 1.5 m, Female socket, straight, Shielded: Yes, LED: No, Sheath material: PUR, Halogen: No
GTIN (EAN)	4050118111200
Qty.	1 pc(s).

**SAIL-M8BG-4S1.5UIE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Dimensions and weights**

Net weight 64 g

**Technical specifications for cable**

Number of poles	4	Core cross-section	0.15 mm <sup>2</sup>
Outside diameter	4.8 ± 0.3 mm	Shielded	Yes
Insulation	PP	Colour coding	blue, orange, white / blue, white / orange
Sheath material	PUR	Sheathing colour	Green
Cable length	1.5 m	Temperature range, stationary	-40...80 °C
Halogen	No	Suitable for cable carriers	Yes
Bending radius, min., stationary	4 x cable diameter	Bending radius, min., moving	7.5 x cable diameter
Acceleration	5 m/s <sup>2</sup>	Speed	180 m/min
Bending cycles	5 Mio	Resistant to welding beads	No

**General technical data**

Version	Female socket, straight	connection thread	M8
Housing main material	PUR	Threaded ring material	Brass, nickel-plated
Coding	none	Protection degree	IP67
Contact surface	Gold-plated	LED	No
Rated voltage	30 V	Rated current	4 A
Insulation resistance	10 <sup>8</sup> Ω	Temperature range of housing	-25...+80 °C
Tightening torque	M8: 0.5 - 0.6 Nm	Plugging cycles	≥ 100
Pollution severity	3	jumpered	No

**Classifications**

ETIM 5.0	EC001855	ETIM 6.0	EC002599
eClass 6.2	27-27-92-18	eClass 7.1	27-27-92-18
eClass 8.1	27-27-92-18	eClass 9.0	27-06-03-11
eClass 9.1	27-06-03-08		

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Brochure/Catalogue	<a href="#">FL FIELDWIRING EN</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>


**Data sheet**

**SAIL-M8BG-4S1.5UIE**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com


**Drawings**

**Dimensioned drawing**

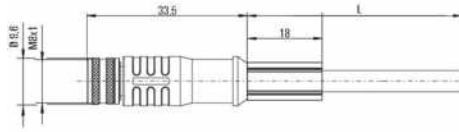


Pin

**Pole scheme**

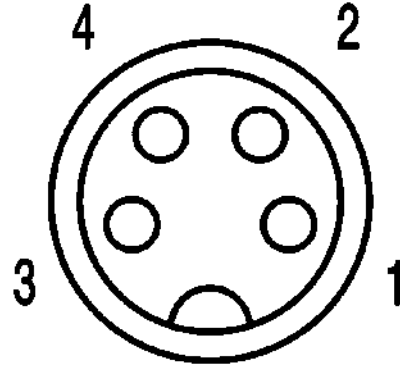

Socket

**Wiring diagram**

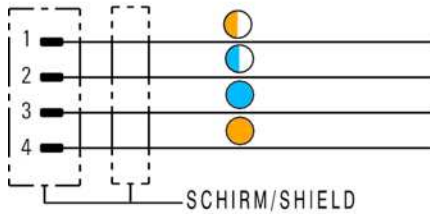

**The ideal tool, the Screwty® with torque function**



Light, securely screwed-in round plug-in connectors. Screwty set DM / VPE: 1 / Order No.: 1920000000 Adapters: M12, M12 F, M8, M8 F