

**IE-FM5Z2LO0002MLD0LDO-X**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
[www.weidmueller.com](http://www.weidmueller.com)



Assembled IE cables, FO

**General ordering data**

Version	Patch cable, duplex clip included, LC-Duplex IP 20, LC-Duplex IP 20, 50 µm, LSZH, 2 m
Order No.	<a href="#">1433940020</a>
Type	IE-FM5Z2LO0002MLD0LDO-X
GTIN (EAN)	4050118242645
Qty.	1 pc(s).

Creation date December 1, 2023 2:05:04 PM CET

Catalogue status 24.11.2023 / We reserve the right to make technical changes.

## IE-FM5Z2LO0002MLD0LDO-X

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Dimensions and weights

Length	2 m	Length (inches)	78.74 inch
Net weight	30 g		

### Temperatures

Operating temperature	-20 °C...70 °C
-----------------------	----------------

### Cable specific standards

Specification for checking the symmetrical communication cabling	IEC 61935-3	Specification for twisted-pair device connection cables	IEC 61156-6, DIN EN 50288-4-2
--	-------------	---	-------------------------------

### General standards

Connector standard	IEC 61754-20
--------------------	--------------

### Standards

Connector standard	IEC 61754-20
--------------------	--------------

### Cable structure

Cable layout	ZIPCORD	Core diameter	50 µm
Material sheath	LSZH	Primary coating	245 µm
Sheath diameter	2.0 * 4.1 mm	Sheathing colour	orange
Standard designations	I-V(ZN)H		

### Mechanical and material properties of cable

Halogen	No	Min. bending radius, once only	20 mm
Min. bending radius, repetitive	40 mm	Resistance to spread of flame	IEC 60754-2

### Plug

Plug	Cable side	left
	Version of contact face	LC-Duplex
	Protection degree (IP)	IP20
	Gender of contact	male contact
	Outlet direction	straight
	Version of connector	plug
	Housing main material	Plastic
	Status indicator available	No
	Shielding available	No
	Cable side	right
	Version of contact face	LC-Duplex
	Protection degree (IP)	IP20
	Gender of contact	male contact
	Outlet direction	straight
	Version of connector	plug
	Housing main material	Plastic
	Status indicator available	No
	Shielding available	No
Plug left	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded	
Plug right	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded	

Creation date December 1, 2023 2:05:04 PM CET

## IE-FM5Z2LO0002MLD0LDO-X

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Plug, left

Connector left	Plug left	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded
LC-Duplex IP 20		

## Plug, right

Connector right	Plug right	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded
LC-Duplex IP 20		

## Classifications

ETIM 6.0	EC002607	ETIM 7.0	EC002607
ETIM 8.0	EC002607	ETIM 9.0	EC002607
ECLASS 9.0	27-06-10-03	ECLASS 9.1	27-06-10-03
ECLASS 10.0	27-06-10-03	ECLASS 11.0	27-06-10-03
ECLASS 12.0	27-06-10-03	ECLASS 13.0	27061003

## Approvals

ROHS	Conform
------	---------

## Downloads

User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

**Data sheet**


**IE-FM5Z2LO0002MLD0LDO-X**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Detailed drawing**

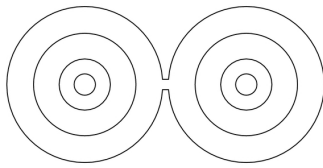

**IE-FM5Z2LO0002MLD0LDO-X**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**V0 material**



SlimFix are conductor and cable markers with a space-saving design. The markers can be fitted even after the conductor has been installed. They consist of halogen-free material and comply with flammability rating V0/V2. SlimFix is an acknowledged and accredited marker type for traffic engineering applications. The SF tool allows easy installation, even in case of small markers.

**Advantages:**

- Halogen-free material
- Flammability rating V0/V2
- Approved and accredited markers for traffic engineering applications, etc.
- Has to be fixed with cable ties if the conductor cross-section is larger than 16.0 mm<sup>2</sup>
- Markers in proven MultiCard format

**General ordering data**

Type	VT SF 6/21 MC NE WS V0	Version
Order No.	<a href="#">1730560001</a>	SlimFix, Conductor and cable markers, 5.8 - 7.8 mm, 21 x 8.4 mm,
GTIN (EAN)	4008190954611	white
Qty.	160 pc(s).	
Type	VT SF 5/21 MC NE WS V0	Version
Order No.	<a href="#">1689470001</a>	SlimFix, Conductor and cable markers, 4.8 - 7.4 mm, 21 x 7.4 mm,
GTIN (EAN)	4008190872571	white
Qty.	160 pc(s).	