

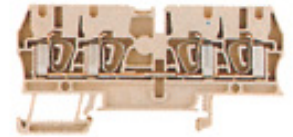
# Rail Mounted Terminal Blocks

## 1683430000

When good enough just isn't good enough



### ZDU 2.5/4AN


[Email to a Friend](#)
[View Catalog Page](#)
[Sales Information](#)
[Back to StepSearch](#)
[Catalog Home](#)

Representative Photo

### Technical Information

Clamping Type	Tension Clamp
Series	Z Series
Rail Type	TS 35
Function	Feed Through
Configuration	Branch
Wire Size	#26...12 AWG
Current	25 A
Voltage	600 V
Color/Material	Yellow Wemid
Wire Entry	90° Top Entry

### Technical Data

	UL	CSA	VDE
Rated Voltage	600 V	600 V	800 V
Rated Current	25 A	20 A	24 A
Wire Size	#26...12 AWG	#26...12 AWG	2.5 mm <sup>2</sup>

### Additional Data

Width/Length/Height mm (in.)	5/79/39 (.2"/3.11"/1.54")
Insulation Stripping Length mm (in.)	10 (.39")
Flammability Class	UL 94 (V0)

### Suggested Accessories

[DIN-rail](#)
[End plate/partition \(ZAP/TW\)](#)
[Ferrules](#)
[Markers \(SchT\)](#)
[Marking pens](#)
[Marking system \(WS/ZS\)](#)
[Marking tags \(DEK\)](#)
[Mounting brackets](#)

[Test plugs/socket](#)

[Tools](#)

[ZQV jumpers](#)

**Product Liability** The above information describes our products. It does not constitute guaranteed properties and is not intended to affirm the suitability of a product for a particular application. Regrettably, omissions and exceptions cannot be completely ruled out. Technical data are always specified by their average values. Exact data and the tolerances which apply to our processes can be requested from:

Weidmüller - North America  
United States 001 (800) 849-9343  
Canada 001 (800) 268-4080

or

Weidmüller - Germany  
Telephone operator 0049 (-5252) 960-0