


SlimFix Clip SFC 1/12 MC NE GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

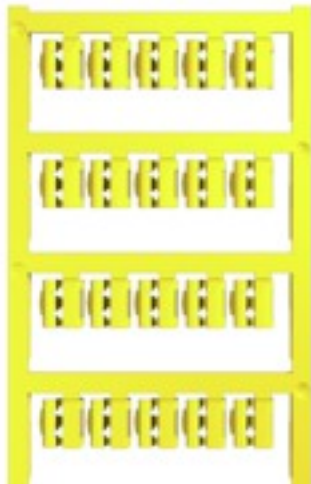

Similar to illustration



The SlimFix Clip combines two advantages: its unique closure mechanism offers the reliability of a closed marker with the ease of installation of an open marker. The clip mechanism allows quick and convenient installation of the marker even after the conductor has been installed. SlimFix Clips are suitable for conductors and cables with an outside diameter of up to 5 mm. The large marking surface - up to 30 mm - enables long character strings. The material is halogen-free and complies with flammability rating V2.

- Halogen-free material
- Flammability rating V2
- Fast installation without tools
- Markers in proven MultiCard format
- Available in the lengths of 12 mm, 21 mm and 30 mm

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	SFC 1/12 MC NE GE
Order No.	1747320004
Version	SlimFix Clip, Conductor and cable markers, 2 - 3.5 mm, 12 x 5.8 mm, yellow
GTIN (EAN)	4008190995508
Qty.	200 pc(s).
compatible printer	1324380000 2438520000 2438510000

SlimFix Clip
SFC 1/12 MC NE GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data
Dimensions and weights

Width	5.8 mm	Width (inches)	0.228 inch
Height	12 mm	Height (inches)	0.472 inch
Depth	7 mm	Depth (inches)	0.276 inch
Net weight	0.475 g		

General data

Colour	yellow	Halogen	No
Material	Polyamide 66	Material colour according to resistance code	4
Operating temperature range	-40...100 °C	Recommended industries	Machinery
Size of labelling field	12 x 4.1 mm	Type of printing	neutral
UL 94 flammability rating	V-2	Width	5.8 mm

Conductor and cable markers

Conductor O.D.	2 - 3.5 mm	Conductor O.D., max.	3.5 mm
Conductor O.D., min.	2 mm	Conductor cross-section, max.	2.5 mm ²
Conductor cross-section, min.	0.75 mm ²	Halogen	No

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
eClass 9.0	27-40-04-01	eClass 9.1	27-40-04-01
eClass 10.0	27-40-04-01	UNSPSC	44-12-17-08

Approvals

ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 8 SAI 15/16 EN
Engineering Data	EPLAN, WSCAD, Zuken E3,S
Engineering Data	STEP
Software	M-Print PRO configuration file

Data sheet

**SlimFix Clip
SFC 1/12 MC NE GE**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

