

Cabtite
CABTITE KEL 24/4**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

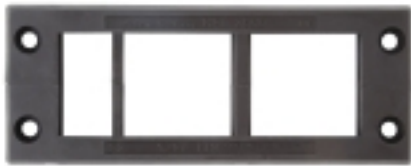

Cabtite enables you to feed pre-assembled lines through the electrical cabinet wall while maintaining IP54-level protection. As the cable does not have to be split, the manufacturer's guarantee is not invalidated.

General ordering data

Type	CABTITE KEL 24/4
Order No.	1825930000
Version	Cable entry strips, Cabtite, Plastic, Black, Height: 58 mm, Width: 147 mm, Depth: 17 mm, -40 °C - 140 °C
GTIN (EAN)	4032248328642
Qty.	10 pc(s).

Cabtite

CABTITE KEL 24/4

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	147 mm	Width (inches)	5.787 inch
Height	58 mm	Height (inches)	2.283 inch
Depth	17 mm	Depth (inches)	0.669 inch
Net weight	113.4 g		

General information

Material	Plastic	Operating temperature range, max.	140 °C
Operating temperature range, min.	-40 °C		

Classifications

ETIM 3.0	EC000441	ETIM 4.0	EC000441
ETIM 5.0	EC000441	ETIM 6.0	EC002624
UNSPSC	30-21-18-01	eClass 5.1	27-14-92-01
eClass 6.2	27-14-92-01	eClass 7.1	27-14-92-01
eClass 8.1	27-14-92-01	eClass 9.0	27-14-44-38
eClass 9.1	27-18-92-65		

Approvals

ROHS	Conform
------	---------

Downloads

Brochure/Catalogue	CAT 5 ENCL 17/18 EN
Engineering Data	EPLAN.WSCAD