


**EL 100 MM GN 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

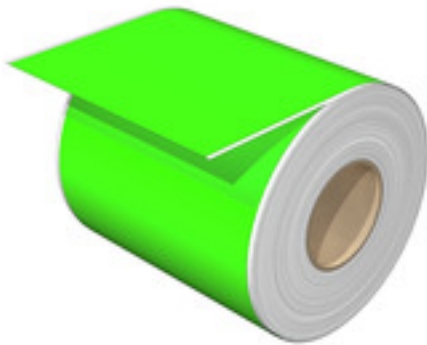**Customised identification: EL**

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

**Your benefits with MultiMark**

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

**General ordering data**

Version	THM, Device markers, 100 x , green
Order No.	<a href="#">2528370000</a>
Type	EL 100 MM GN 30M
GTIN (EAN)	4050118539264
Qty.	1 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a>

Creation date December 4, 2023 1:52:41 PM CET

Catalogue status 24.11.2023 / We reserve the right to make technical changes.

## EL 100 MM GN 30M

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.004 inch
Height	100 mm	Height (inches)	3.937 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	844 g		

### Temperatures

Operating temperature range	-40...120 °C
-----------------------------	--------------

### General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	green	Halogen	No
Length	30,000 mm	Material	Polyester
Number per roll	1	Operating temperature range	-40...120 °C
Operating temperature range, max.	120 °C	Operating temperature range, min.	-40 °C
UL 94 flammability rating	V-0	Version	halogen-free, Self-adhesive

### Device markers

Halogen	No
---------	----

### Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27281104

### Approvals

ROHS	Conform
------	---------

### Downloads

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--


**Data sheet**

**EL 100 MM GN 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

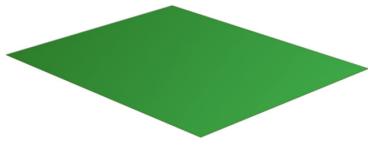

## EL 100 MM GN 30M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	<a href="#">2005070000</a>	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

### THM MULTIMARK

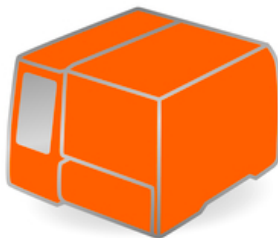

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data


Type	THM MMP ROLLER 115
Order No.	<a href="#">1357420000</a>
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

Type	THM MMP EXT.RH
Order No.	<a href="#">1302920000</a>
GTIN (EAN)	4050118102307
Qty.	1 pc(s).

**EL 100 MM GN 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

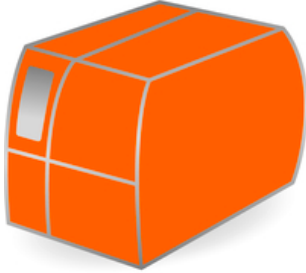**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MM PLUS ROLLER 110
Order No.	<a href="#">2672590000</a>
GTIN (EAN)	4050118708097
Qty.	1 pc(s).