


VT-TM 2/12 HF-V0

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

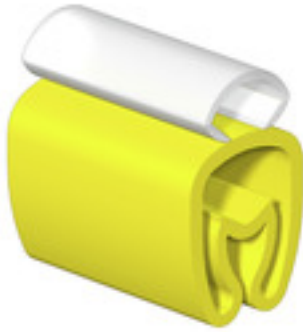

General ordering data

Version	x 5.3 mm, TPU, Colour: yellow, Transparent
Order No.	2571310000
Type	VT-TM 2/12 HF-V0
GTIN (EAN)	4050118608373
Qty.	100 pc(s).

VT-TM 2/12 HF-V0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	12 mm	Height (inches)	0.472 inch
Width	5.3 mm	Width (inches)	0.209 inch
Net weight	0.47 g		

General data

Colour	yellow, Transparent	Halogen	No
Material	TPU	Operating temperature range, max.	90 °C
Operating temperature range, min.	-30 °C	Printed characters	without
Type of printing	neutral	UL 94 flammability rating	V-0
Width	5.3 mm		

Conductor and cable markers

Conductor O.D., max.	4 mm	Conductor O.D., min.	2.5 mm
Conductor cross-section, max.	2.5 mm ²	Conductor cross-section, min.	0.75 mm ²
Halogen	No		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27281102

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--