

KEBIHS404020S2N1 AL**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The new Klippon® EBi enclosure series has been specially designed for use in industrial environments. It reliably meets all requirements for use in harsh environments and is characterised by attractive performance features. The cost-effective stainless steel enclosures allow a very economical calculation and are also suitable for projects with a limited budget. In addition to Klippon® EBi for industrial applications, there is Klippon® EBx for hazardous areas. Enclosures with cULus approvals are available on request.

General ordering data

Version	Klippon EBi HS (Essential Box industrial - Hinged Screws), Enclosures, Height: 400 mm, Width: 400 mm, Depth: 200 mm, Gland plates: Bottom, Material: Stainless steel 1.4301 (304), untreated, silver
Order No.	8000090354
Type	KEBIHS404020S2N1 AL
GTIN (EAN)	4064675855675
Qty.	1 pc(s).

Creation date December 4, 2023 3:27:24 PM CET

KEBIHS404020S2N1 AL**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	200 mm	Depth (inches)	7.874 inch
Height	400 mm	Height (inches)	15.748 inch
Width	400 mm	Width (inches)	15.748 inch
Net weight	9,515.05 g		

Temperatures

Operating temperature	-40 °C...85 °C
-----------------------	----------------

General information

Enclosure attachment	Installation through the housing rear wall	Flange plate	Yes
Gland plates	Bottom	Impact resistance	10 J version standard
Lid attachment	M5 hexagonal screw with slot and 10mm distance across flats + hinge	Material	Stainless steel 1.4301 (304)
Material thickness of cover	1.5 mm	Material thickness of enclosure	1.5 mm
Material thickness of flange	3 mm	Note: protection class	IP protection is only given after wall mounting using the enclosed sealing washers.
Operating temperature, max.	85 °C	Operating temperature, min.	-40 °C
Protection degree	IP66	Seal material	Chloroprene
Silicone	No	Surface finish	untreated

horizontal assembly

WDU 10 / ZDU 10	2x19	WDU 16 / ZDU 16	2x16
WDU 2,5 / ZDU 2,5 / IDU 2,5	3x39	WDU 35 / ZDU 35	1x11
WDU 4 / ZDU 4	3x32	WDU 6 / ZDU 6	2x24

vertical assembly

WDU 10 / ZDU 10	1x30	WDU 16 / ZDU 16	1x24
WDU 2,5 / ZDU 2,5 / IDU 2,5	2x59	WDU 35 / ZDU 35	1x18

Classifications

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ETIM 9.0	EC000261
ECLASS 9.0	27-18-01-01	ECLASS 9.1	27-18-92-90
ECLASS 10.0	27-18-01-01	ECLASS 11.0	27-18-01-01
ECLASS 12.0	27-18-01-01	ECLASS 13.0	27180101

Approvals

Approvals



Data sheet**KEBIHS404020S2N1 AL****Weidmüller Interface GmbH & Co. KG**
Klingenbergstraße 26
D-32758 Detmold
Germanywww.weidmueller.com**Technical data****Downloads**


Approval/Certificate/Document of Conformity	EU Declaration of Conformity - Klippon EBi Empty Enclosures - DoC KEBI DE PS2650 220428 0011SS00
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format

KEBIHS404020S2N1 AL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

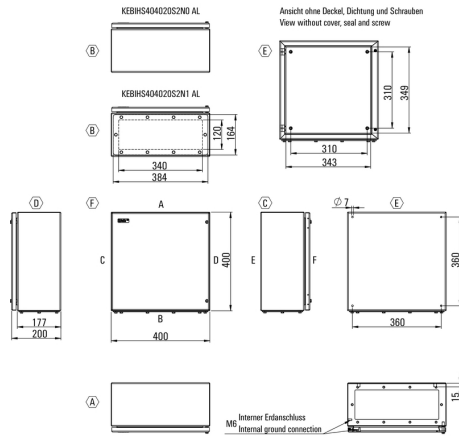

KEBIHS404020S2N1 AL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Spacer



Stainless steel spacers in three lengths to increase the distance between the mounting rails or DIN rails and the rear wall of the enclosure.

General ordering data

Type	SP M6 20 MSZN	Version
Order No.	3896200000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850234	Depth: 20 mm, Material: Steel, silver
Qty.	2 pc(s).	
Type	SP M6 15 MSZN	Version
Order No.	3896100000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190857851	Depth: 15 mm, Material: Steel, silver
Qty.	1 pc(s).	
Type	SP M6 30 MSZN	Version
Order No.	3896300000	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850241	Depth: 30 mm, Material: Steel, silver
Qty.	2 pc(s).	

Document holders



Document holders for the proper storage of documents in the enclosure.

General ordering data

Type	DOHA KEB A6 S4B R	Version
Order No.	8000075807	Klippon EB (Essential Box), Enclosures, Riveted, Height: 95 mm, Depth:
GTIN (EAN)	4064675425359	20 mm, Material: Stainless steel 1.4404, silver
Qty.	1 pc(s).	
Type	DOHA KEB A4 S4B R	Version
Order No.	8000075809	Klippon EB (Essential Box), Enclosures, Riveted, Height: 175 mm,
GTIN (EAN)	4064675425656	Depth: 20 mm, Material: Stainless steel 1.4404, silver
Qty.	1 pc(s).	
Type	DOHA KEB A5 S4B R	Version
Order No.	8000075808	Klippon EB (Essential Box), Enclosures, Riveted, Height: 125 mm,
GTIN (EAN)	4064675425649	Depth: 20 mm, Material: Stainless steel 1.4404, silver
Qty.	1 pc(s).	

KEBIHS404020S2N1 AL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type label holder




There are a variety of designed label holders available for prominent display as required and for additional nameplates as needed.

General ordering data

Type	TPSDHA KEB 130X50 S4B R	Version
Order No.	8000075816	Klippon EB (Essential Box), Enclosures, Riveted, Height: 50 mm, Width:
GTIN (EAN)	4064675425366	171 mm, Depth: 16.5 mm, Material: Stainless steel 1.4404 (316L),
Qty.	1 pc(s).	Brushed, silver
Type	TPSDHA KEB 100X25 S4B R	Version
Order No.	8000075818	Klippon EB (Essential Box), Enclosures, Riveted, Height: 25 mm, Width:
GTIN (EAN)	4064675425632	141 mm, Depth: 16.5 mm, Material: Stainless steel 1.4404 (316L),
Qty.	1 pc(s).	Brushed, silver

Slotted screwdriver

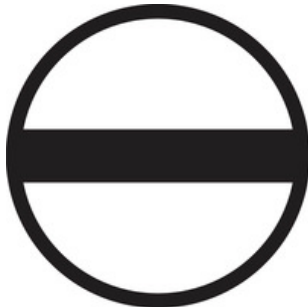

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

Type	SDIS SLIM 1.2X6.5X150	Version
Order No.	2749640000	Mounting tool, Blade width (B): 6.5 mm, Blade length: 150 mm, Blade
GTIN (EAN)	4050118896381	thickness (A): 1.2 mm
Qty.	1 pc(s).	

KEBIHS404020S2N1 AL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Mounting feet



With the additionally available mounting feet, the enclosures can also be mounted from outside the enclosure.

General ordering data

Type	KEB MOFT SMALL S4 SET	Version
Order No.	2660200318	Klippon EB (Essential Box), Mounting foot, Height: 38 mm, Width: 55
GTIN (EAN)	4064675275695	mm, Depth: 10.5 mm, Material: Steel, untreated, silver
Qty.	1 pc(s).	

Installation material



Integrate, expand and customise - the perfect supplement to every application

The fully structured range of system accessories for the new Klippon® TB enclosure series allows you to easily adapt the enclosures to meet the specific requirements of every application.

Mounting hardware kits

Mounting hardware kits are available for quick and easy installation of type label holders, document holders and rain hoods.

The **label fastening set – SD** is required to install a plastic (Trafolyte) ID or type label. With the aid of this set can you mount the ID or type label directly on the enclosure cover. The label fastening set has been specially developed for this purpose. Only by using this fastening set can you ensure that there will be no leaks into the enclosure or damage to the label.

The **universal fastening set – TPSD** has been developed to enable secure and quick installation of type label holders, rain covers or document holders, for example. By using this fastening set, the risk of leaks can be minimised, if not avoided.

General ordering data

Type	LKSC M6X8 A2 TX30	Version
Order No.	2704960000	Klippon TB (Terminal Box), Set of fixings, Height: 11.3 mm, Width:
GTIN (EAN)	4050118753196	13.6 mm, Depth: 13.6 mm, Material: Stainless steel, rust-proof,
Qty.	500 pc(s).	untreated, silver

KEBIHS404020S2N1 AL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Mounting plates



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

General ordering data

Type	KEB MOPL 4040 S2N H	Version
Order No.	8000074319	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width:
GTIN (EAN)	4064675425281	340 mm, Depth: 1.5 mm, Material: Stainless steel 1.4301 (304),
Qty.	1 pc(s).	untreated, silver
Type	GFSC M5X10 TX20 SET	Version
Order No.	1274150000	Klippon EB (Essential Box), Mounting screw, Height: 13.3 mm, Width:
GTIN (EAN)	4050118063820	8.5 mm, Depth: 8.5 mm, Material: Steel, galvanized, galvanic zinc
Qty.	1 pc(s).	plated and passivated, silver
Type	KEB MOPL 4040 MSZN	Version
Order No.	8000074173	Klippon EB (Essential Box), Mounting plate, Height: 340 mm, Width:
GTIN (EAN)	4064675425182	340 mm, Depth: 1.5 mm, Material: Sheet steel, galvanized, silver
Qty.	1 pc(s).	