

H0,75/14TS HBL**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-2083

www.weidmueller.com

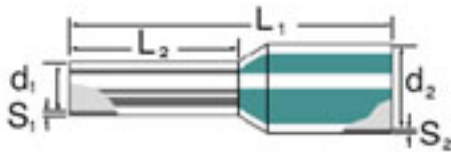

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|--|
| Order No. | 9018550000 |
| Type | H0,75/14TS HBL |
| Version | Wire end ferrule, 0.75 mm ² , 8 mm. Colour code: Weidmüller, Light blue |
| GTIN (EAN) | 4008190207991 |
| Qty. | 500 pc(s). |

H0,75/14TS HBL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-2083
 www.weidmueller.com

Technical data

Dimensions

| | | | |
|--------|-------|------------|---------|
| Length | 14 mm | Net weight | 0.094 g |
|--------|-------|------------|---------|

Product data

| | | | |
|-------------------------------|----------------------|-------------------------------|---------|
| Conductor cross-section | 0.75 mm ² | Contact surface length (L2) | 8 mm |
| Contact surface diameter (D1) | 1.2 mm | Collar diameter (D2) | 3.4 mm |
| Metal sleeve thickness (S1) | 0.15 mm | Plastic collar thickness (S2) | 0.25 mm |

Classifications

| | | | |
|------------|-------------|------------|-------------|
| ETIM 2.0 | EC000005 | ETIM 3.0 | EC000005 |
| UNSPSC | 31-16-31-02 | eClass 4.1 | 27-06-07-01 |
| eClass 5.1 | 27-40-02-01 | eClass 6.0 | 27-40-02-01 |
| eClass 7.0 | 27-40-02-01 | | |

Product information

| | |
|------------------------|--|
| Description of article | Wire end ferrule with plastic collar, special size, light blue |
|------------------------|--|

Approvals

Approvals

