

H10/30S ZH EB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-2083

www.weidmueller.com

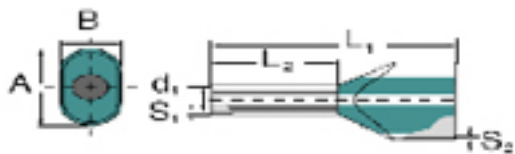

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Order No.	9018870000
Type	H10/30S ZH EB
Version	Wire end ferrule, 10 mm ² , 18 mm, Colour code: Weidmüller, Ivory
GTIN (EAN)	4032248105823
Qty.	100 pc(s).

H10/30S ZH EB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-2083
 www.weidmueller.com

Technical data

Dimensions

Length	30 mm	Net weight	1.07 g
--------	-------	------------	--------

Product data

Conductor cross-section	10 mm ²	Contact surface length (L2)	18 mm
Collar height (A)	13.4 mm	Collar width (B)	7.6 mm
Contact surface diameter (D1)	6.5 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm		

Classifications

ETIM 2.0	EC000005	ETIM 3.0	EC000005
UNSPSC	31-16-31-02	eClass 4.1	27-06-07-01
eClass 5.1	27-40-02-01	eClass 6.0	27-40-02-01
eClass 7.0	27-40-02-01		

Product information

Description of article	Twin wire end ferrule, ivory
------------------------	------------------------------

Approvals

Approvals

